


# Datasheet

## LED Indicator

RS ITEM NO 208-863

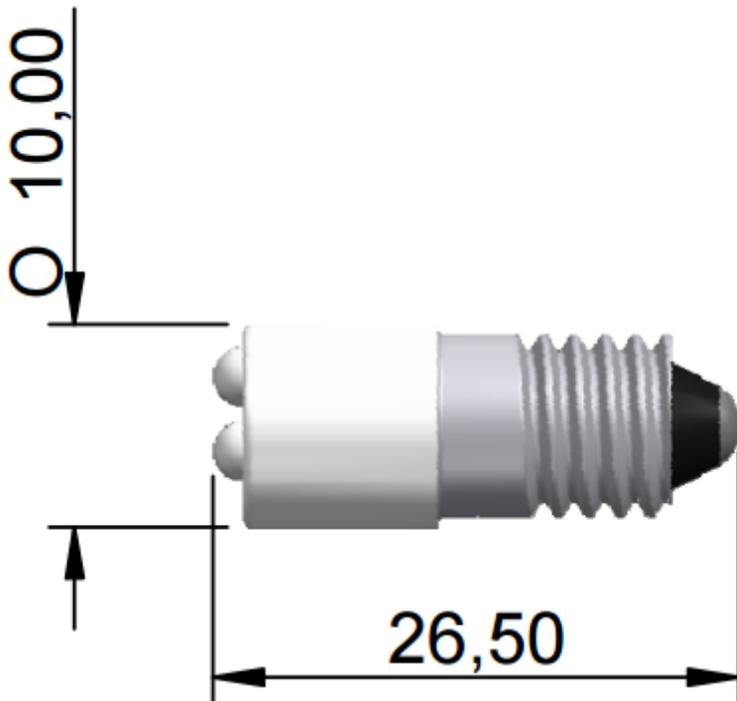

LED/Multiled	LED	Optimum voltage (V)	130Vac/Dc	Intensity	710mcd
Mounting Size	10x25mm	Rectifier	Half Wave		
Mounting Finish		AC current	5mA		
Protection	-	DC current			
Mount Holder	E10	Voltage Tolerance (%)	10%		
Chip Qty	3	Optimum temperature (°C)	-30°C...+60°C		
Indicator colour	White	Storage temperature (°C)	-30°C...+60°C		
Wavelength (nm)		Contact Tab	E10 Cap		



*Dimension in mm (typical), not to scale.  
We reserve the right to make changes without further notice to this product to improve reliability, function or design.*