


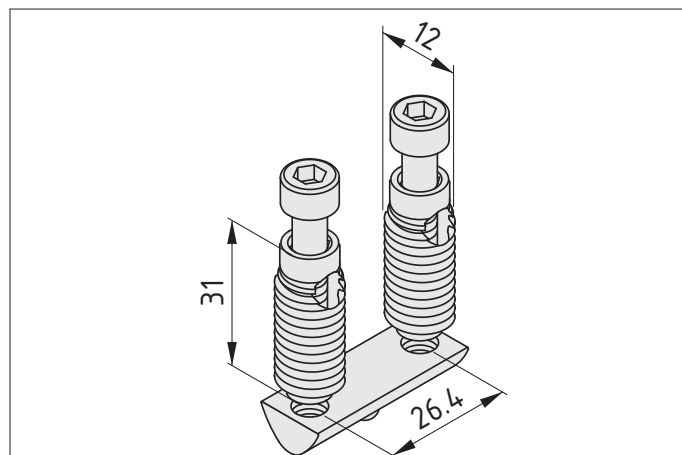

Automatic-Fastening Set 8 40 from item joins two Line 8 profiles at a right angle to create a connection that is highly resistant to displacement, torsion and bending. The T-Slot Nut with two threads makes it easier to fasten both Automatic Fasteners in the modular dimension of 40 mm. The fastener can be used to prevent twisting. The Automatic Fasteners are each screwed into a profile groove and do not require any profile machining. Profiles can be retrofitted to constructions and moved at any time.



Scope of Delivery

2 Automatic Fasteners 8, St, bright zinc-plated
 2 Hexagon Socket Head Cap Screws DIN 912-M6x40, St, bright zinc-plated
 T-Slot Nut 8 St 2xM6-36, bright zinc-plated

Technical note

[0.0.672.84](#) For more information, please click here!

Properties	
Article number	0.0.672.84
Delivery unit	1 set
Weight	60.4 g
Torque	14 Nm

Accessoires	
0.0.388.66	Automatic-Fastening Set 8 Cap, black similar to RAL 9005
0.0.616.31	Automatic-Fastening Set 8 Cap, grey similar to RAL 7042
0.0.723.10	T-Slot Nut F 8 St 2xM6-36, bright zinc-plated
0.0.406.38	Key with T-Handle 6 A/F
0.0.026.89	L-Key 5 A/F
0.0.026.54	Ball-Headed Key 5 A/F