

CA-12S1N8A8003 - Cable connector



1116286

<https://www.phoenixcontact.com/in/products/1116286>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



M23, Cable connector, series: CA, straight, shielded: yes, Screw locking mechanism, No. of pos. : 12, Direction of rotation: Standard, contact connection type: Socket, Crimp connection, cable diameter range: 6 mm ... 10 mm, coding: N, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1238467

Your advantages

- Safe use in the field, thanks to high degree of protection
- Connector for flexible on-site assembly
- Consistent EMC protection for reliable transmission of signals
- Crimping connection: vibration- and temperature-resistant assembly

Commercial data

Item number	1116286
Packing unit	1 pc
Minimum order quantity	50 pc
Sales key	ABR
Product key	ABRAEA
GTIN	4063151042059
Weight per piece (including packing)	91.1 g
Weight per piece (excluding packing)	87.07 g
Customs tariff number	85366990
Country of origin	DE

CA-12S1N8A8003 - Cable connector



1116286

<https://www.phoenixcontact.com/in/products/1116286>

Technical data

Notes

Order information:	Order 12 x 1 mm crimp contacts separately
--------------------	---

Product properties

Product type	Circular connector (cable-side)
--------------	---------------------------------

Connector

Insulating body

Note	Order information: Order crimp contacts Ø 1 mm separately
Coding	N
Insulation body material	PA 6.6
Connection method	Crimp connection
Contact switching type	Socket
Application	Signal
Number of positions	12
Direction of rotation	Standard
Connection profile	12
Contact diameter	1 mm
Litz wire cross-section	Signal contacts min. 0.08 mm ²
Litz wire cross-section	Signal contacts max. 1 mm ²
Nominal current per signal contact	8 A
Rated voltage	Signal contact 48 V AC
Rated surge voltage	1.5 kV
Overvoltage category	III
Degree of pollution	3

Housing

Housing material	Turned parts: copper zinc alloy (CuZn), die-cast parts: zinc (GD-Zn)
Type of locking	Screw locking mechanism
Pg screw connection	none
Degree of protection (plugged in)	IP67
Thread type	M23

Seal

External cable diameter	6 mm ... 10 mm
Seal material	FPM

Environmental and real-life conditions

Ambient conditions

Ambient temperature (storage/transport)	15 °C ... 25 °C
---	-----------------

CA-12S1N8A8003 - Cable connector



1116286

<https://www.phoenixcontact.com/in/products/1116286>

Permissible humidity (storage/transport)
--

50 % ... 65 %


CA-12S1N8A8003 - Cable connector

1116286

<https://www.phoenixcontact.com/in/products/1116286>

Drawings

Schematic diagram

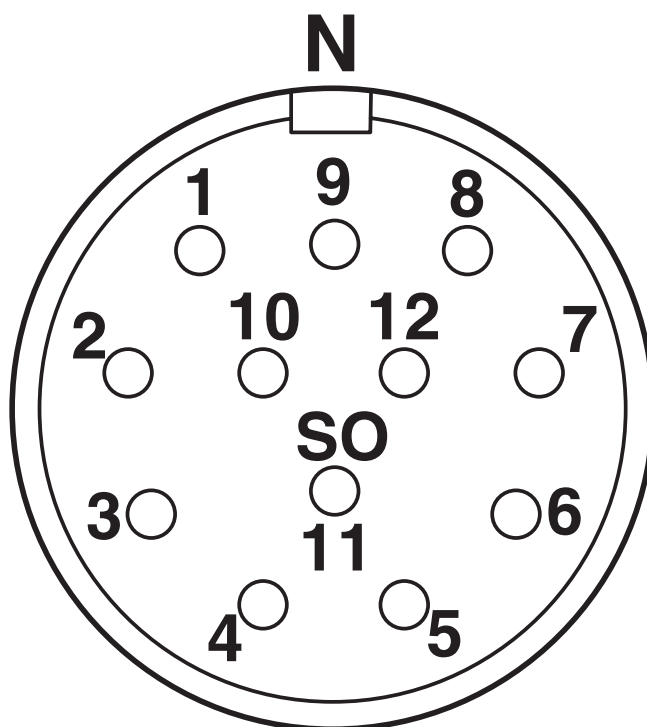

Connector pin assignment

CA-12S1N8A8003 - Cable connector



1116286

<https://www.phoenixcontact.com/in/products/1116286>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1116286>

cUL Recognized Approval ID: E335019-20141210				
	Nominal voltage U_N	Nominal current I_N	Cross section AWG	Cross section mm^2
	48 V	4 A	20	-

UL Recognized Approval ID: E335019-20141210				
	Nominal voltage U_N	Nominal current I_N	Cross section AWG	Cross section mm^2
	48 V	6 A	20	-

cULus Recognized				
------------------	--	--	--	--

CA-12S1N8A8003 - Cable connector



1116286

<https://www.phoenixcontact.com/in/products/1116286>

Classifications

ECLASS

ECLASS-11.0	27440102
ECLASS-12.0	27440116
ECLASS-13.0	27440116

ETIM

ETIM 9.0	EC002635
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

CA-12S1N8A8003 - Cable connector



1116286
<https://www.phoenixcontact.com/in/products/1116286>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)
China RoHS	
Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.
EU REACH SVHC	
REACH candidate substance (CAS No.)	Lead(CAS: 7439-92-1)
SCIP	fb26a1fa-29af-4aff-ac44-6f99d3bfc9cf

CA-12S1N8A8003 - Cable connector



1116286

<https://www.phoenixcontact.com/in/products/1116286>

Accessories

RC-11S2000 - Crimp contact

1596772

<https://www.phoenixcontact.com/in/products/1596772>



Crimp contact, Socket, turned, Single contact, contact diameter: 1 mm, crimp range: 0.08 mm² ... 0.22 mm², Contact release tool not necessary for the 12- and 17-pos. crimp versions of the M23-PRO series, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1241093

RC-12S2000 - Crimp contact

1599600

<https://www.phoenixcontact.com/in/products/1599600>



Crimp contact, Socket, turned, Single contact, contact diameter: 1 mm, crimp range: 0.14 mm² ... 0.56 mm², Contact release tool not necessary for the 12- and 17-pos. crimp versions of the M23-PRO series, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1241093

CA-12S1N8A8003 - Cable connector

1116286

<https://www.phoenixcontact.com/in/products/1116286>



RC-1KS2000 - Crimp contact

1602998

<https://www.phoenixcontact.com/in/products/1602998>



Crimp contact, Socket, turned, Single contact, contact diameter: 1 mm, crimp range: 0.5 mm² ... 1 mm², Contact release tool not necessary for the 12- and 17-pos. crimp versions of the M23-PRO series, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1241572

CA-Z0077 - Metal protective cap

1627224

<https://www.phoenixcontact.com/in/products/1627224>



Metal protective cap, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1245447

CA-12S1N8A8003 - Cable connector

1116286

<https://www.phoenixcontact.com/in/products/1116286>



SF-Z0028 - Torque screwdriver

1607456

<https://www.phoenixcontact.com/in/products/1607456>

Torque screwdriver, series: RC, UC, SH, SF



SF-Z0027 - Hook wrench

1607455

<https://www.phoenixcontact.com/in/products/1607455>

Hook wrench, series: RC, UC, RF, SF



CA-12S1N8A8003 - Cable connector

1116286

<https://www.phoenixcontact.com/in/products/1116286>




RF-Z0014 - Color coding

1620588

<https://www.phoenixcontact.com/in/products/1620588>

Color coding, color: green

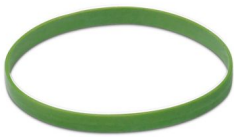


RF-Z0015 - Color coding

1620592

<https://www.phoenixcontact.com/in/products/1620592>

Color coding, color: orange

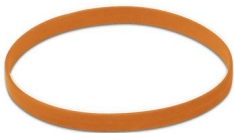

CA-12S1N8A8003 - Cable connector

1116286

<https://www.phoenixcontact.com/in/products/1116286>



RF-Z0016 - Color coding

1620593

<https://www.phoenixcontact.com/in/products/1620593>

Color coding, color: black



RF-Z0003 - Square mounting flange

1607905

<https://www.phoenixcontact.com/in/products/1607905>



Square mounting flange, Axial seal, 4xM3, flange dimensions: 35 mm x 35 mm, series: RF, Alternative product in accordance with RoHS II without Exemption 6c (Pb < 0.1 %) item no.: 1242369

CA-12S1N8A8003 - Cable connector

1116286

<https://www.phoenixcontact.com/in/products/1116286>



RC-22S2300 - Crimp contact

1603330

<https://www.phoenixcontact.com/in/products/1603330>



Crimp contact, Socket, rolled, Taped product, number of pieces per reel: 500, contact diameter: 1 mm, crimp range: 0.22 mm² ... 0.56 mm², Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

RC-22S2400 - Crimp contact

1603332

<https://www.phoenixcontact.com/in/products/1603332>



Crimp contact, Socket, rolled, Taped product, number of pieces per reel: 10000, contact diameter: 1 mm, crimp range: 0.22 mm² ... 0.56 mm², Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

CA-12S1N8A8003 - Cable connector

1116286

<https://www.phoenixcontact.com/in/products/1116286>



RC-22S2000 - Crimp contact

1603327

<https://www.phoenixcontact.com/in/products/1603327>



Crimp contact, Socket, rolled, Single contact, contact diameter: 1 mm, crimp range: 0.22 mm² ... 0.56 mm², Single contact, Item is lead-free in accordance with RoHS II without Exemption 6c (Pb < 0.1 %)

PROT-M23-SG-IT-IP20 - Plastic protective cap

1577206

<https://www.phoenixcontact.com/in/products/1577206>



Plastic protective cap, M23, series: CA, RC, RF, UC, RM

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.
A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420
info@phoenixcontact.co.in