


NA-NB-NC

Preinsulated Ring Terminals

Network Type : Industry

Description :

- Tin-plated copper.
- Barrel with funnel entry.
- Grooves in the barrel for a better electrical contact and a better tensile strength. "N" single crimp series:
- Polyamide insulation sleeve.
- Max. operating temperature: +105°C.
- "Easy entry" conical entry.
- Flammability rating: UL94V2.

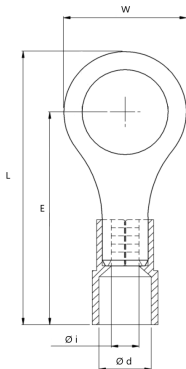

Ref.	Item code	Color	Conductor size (mm ²)		Cable insulation max Ø	Stud size (Ø mm)	Stud Hole Diameter	Ø i	Ø d	W	E	L	Primary Packaging Qty	Secondary Packaging Qty
			Min	Max										
C50NB2-10	7210176	■	1.5	2.5	4,8	10	10.5	2.3	4.5	13,6	24.9	31.5	50	5000

