


Self-aligning ball bearings, cylindrical and tapered bore



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
35	72	17	19	6	0,31	20000	13000	0,32	1207 EKTN9

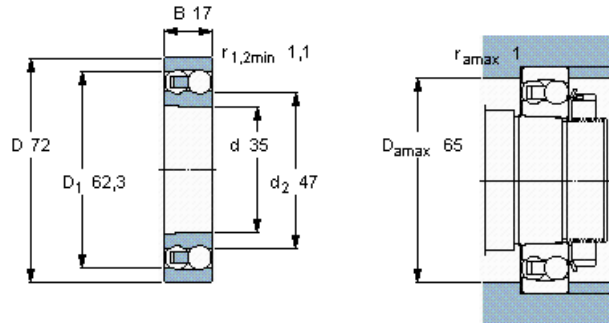

Tapered bore, taper
1: 12

Calculation factors

- e 0,23
- Y_1 2,7
- Y_2 4,2
- Y_0 2,8