


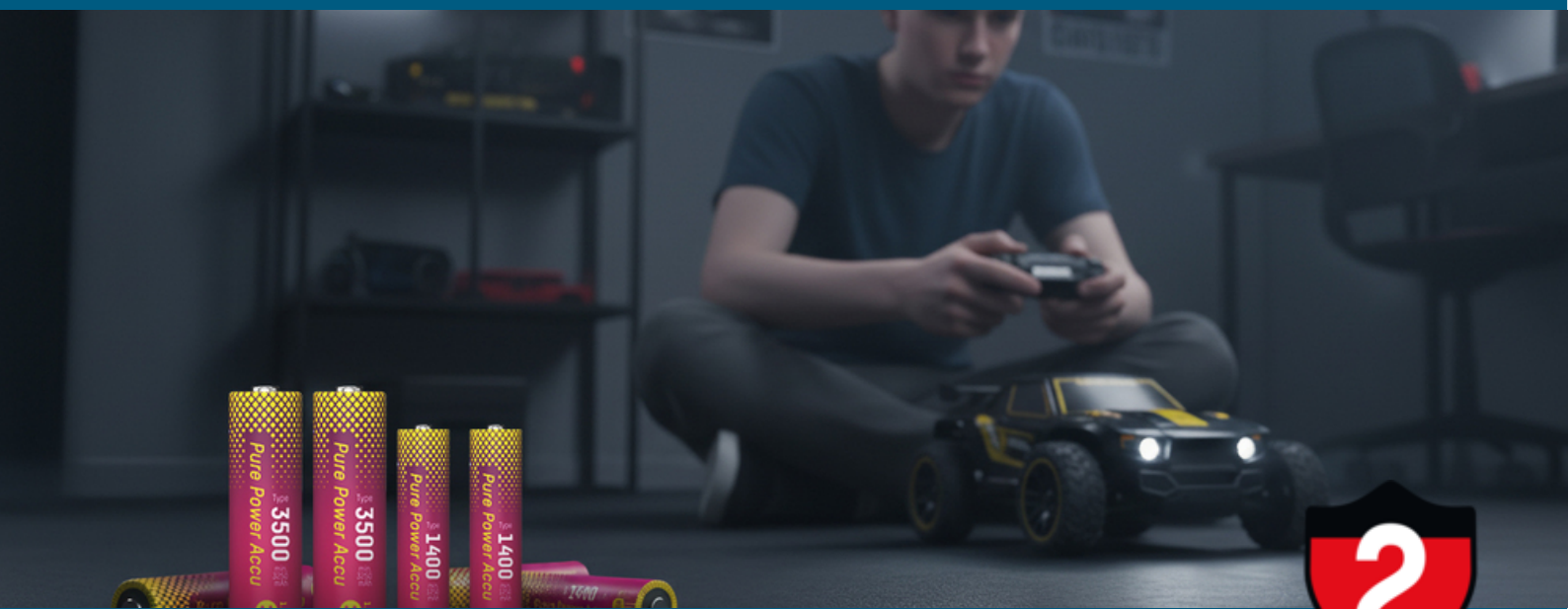

Years Warranty*

ANSMANN Pure Power Set 4× AAA / HR03 battery packs and charging module

4× Li-Ion Pure Power batteries AAA / HR03 type 1400 (min. 1250 mAh) – battery set with maximum capacity, long runtime and protection technology, ideal for devices with high energy requirements and charging module

Features

- High-quality Pure Power AAA / HR03 lithium batteries
- Pure performance: high capacity, power and runtime – even in cold conditions
- Very low self-discharge and high energy efficiency
- Ideal for use in modern LED torches, headlamps, toys, wildlife cameras, etc.
- Integrated protective circuitry protects against overcharging, overload, short circuit and deep discharge
- Max. Continuous discharge current: 1,5 A
- LED charge indicator: Always see how much battery you have left
- Smart charging: The batteries take care of everything – you don't have to worry about a thing
- USB-C connection: modern, fast and flexible
- Includes 4× Li-Ion Pure Power batteries AAA / HR03 type 1400 (min. 1250 mAh), charging module and charging cable (USB-C to USB-C)
- Excellent price-performance ratio



Article number: 1001-0182

Product content: 4 AAA / HR03 Batteries, charging module, USB-C to USB-C charging cable, user manual



Specifications

Nominal voltage	1,5 V
Input voltage	5V DC
Cell size	AAA / HR03
Cell chemistry	Lithium ion
Nominal capacity	1400 mAh
Minimum capacity	1250 mAh
Number of cells in packaging	4
Max. Continuous discharge current	1,5 A
Energy	1,93 Wh
For worldwide use	Yes
Chargeable cell chemistry	Lithium ion
Chargeable cells	AAA / HR03 / AA / HR6
Charging current AAA	600
Charging current AA	600
suitable for	LED torches, headlamps, toys, wildlife cameras, etc.
Color	pink / yellow / white
Packaging	cardboard box
Operating temperature	0 - 25 °C
Storage temperature	-20 - 60 °C
Dimensions	65 × 25 × 75 mm