



Brand of NTN corporation

Technical data

UCPA207

Bearing units




grey cast housing, radial insert ball bearing with socket set screws, seal with slinger, for low-temp. applications

KIT CONTENT

UC207G2, PA207

VISUAL (S)

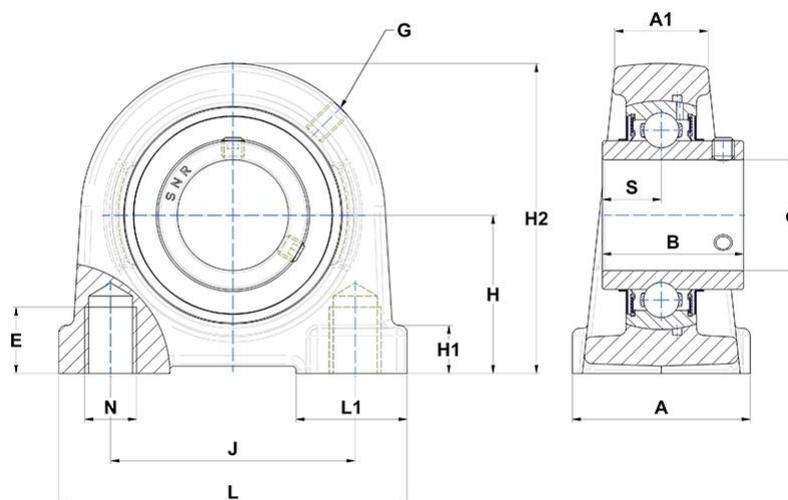

PRODUCT DEFINITION

Brand	SNR
A - Housing width	48 mm
A1 - Housing top width	27 mm
B - Width of Inner Ring	42,9 mm
d - Shaft diameter	35 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

E - Mounting hole thread depth	20 mm
G - Grease fitting	M6x1
H - Distance mounting base to centerline spheric. seating diam.	47,6 mm
H1 - Housing foot height	13 mm
H2 - Housing height	95 mm
J - Mounting holes distance	80 mm
L - Housing length	110 mm
L1 - Housing foot length	30 mm
N - Mounting hole dimension	M14
S - Distance front side/bearing centre	17,5 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	25700000 mN
C0 - Static load rating	15200000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	1,47 kg
Recommended tightening torque for set screw	11.5 N-m

