


# Deep groove ball bearings, single row, seal on both sides

Product information

Tolerances , see also text  
 Radial internal clearance , see also text  
 Recommended fits  
 Shaft and housing tolerances

Principal dimensions			Basic load ratings		Fatigue load limit $P_u$	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
60	95	18	30,7	23,2	0,98	-	4300	0,42	6012-2RS1 *

\* - SKF Explorer bearing

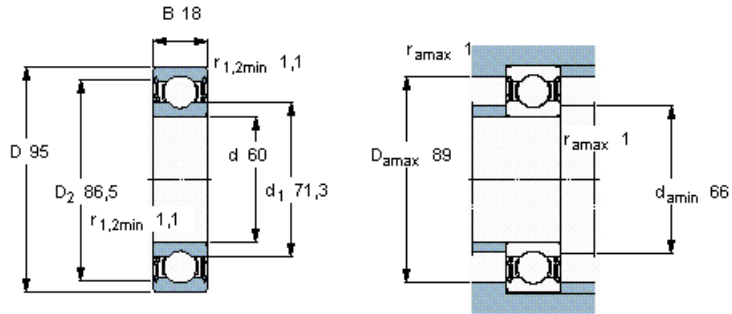

### Calculation factors

$k_f$  0,025  
 $f_0$  16