


FEATURES

- **Flexible design:** Easily adapts to different surfaces and shapes, allowing for creative installations
- **IP54 rating:** Offers protection against dust and water splashes, suitable for indoor and semi-outdoor use
- **Neutral white LED colour:** Provides a balanced light output, ideal for workspaces and living areas
- **60 LEDs per metre:** Ensures uniform light distribution across the strip
- **4.8 W/m power consumption:** Energy-efficient operation, reducing electricity costs
- **415 lm/m luminous flux:** Delivers bright and effective lighting
- **16.6 mm LED pitch:** Ensures even light coverage without dark spots
- **24 V dc voltage:** Compatible with standard power supplies for easy integration

RS PRO Flexible LED Strip Light, 5 m

RS Stock No: 558-396

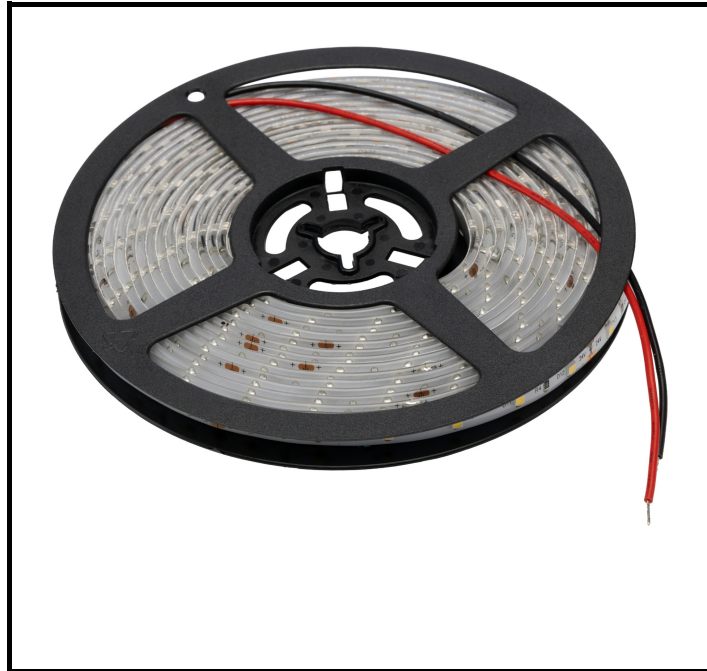

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

The RS PRO Flexible LED Strip Light is designed for versatile lighting solutions, offering a neutral white illumination ideal for various settings. With a strip length of 5 metres, it provides consistent and efficient lighting, making it suitable for both commercial and residential applications.

General Specifications

Colour Temperature	3800-4200 K
Flexible/Rigid	Flexible
LED Colour	Neutral White
LED Pitch	16.6 mm
Number of LEDs Per Metre	60
Product Type	LED Strip Light
Typical Luminous Flux (lm/m)	415 lm/m

Protection Category

IP Rating	IP54
-----------	------

Electrical Specifications

Power Per Metre	4.8 W/m
Voltage	24 V dc

Approvals

Standards/Approvals	CE, RoHS
---------------------	----------

Mechanical Specifications

Strip Length	5 m
Strip Width	8 mm

