


Product Name // M12 Series A Code PVC Right-Angle Overmould Flex Cable Connector 5 Contact Socket Pre-Wired With 1M PVC Jacket Cable

 [View Product Page](#)

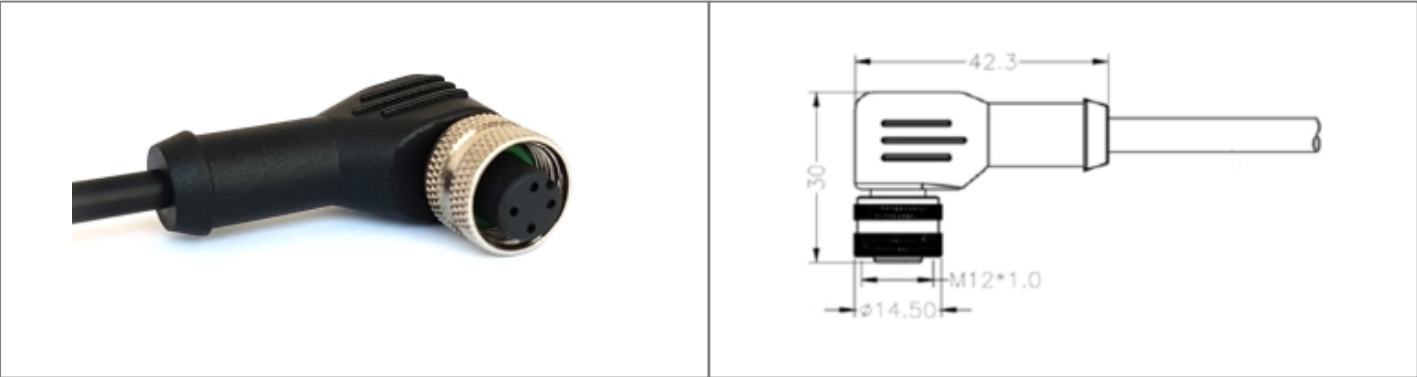

// Product Description:

- M12 Series Right-Angle Overmould Flex Body Connectors
 - Water and dustproof to IP67 when mated with compatible connector
 - Pin or Socket
 - 3, 4, 5, 8, 12 Contact (3, 8, 12 Contact are A Code, 4 Contact are choice of A Code or D Code, 5 Contact are choice of A Code or B Code)
- Overmould cable Termination with choice of lead lengths and choice of PVC or PUR jacket cable, depending on part code
 - Choice of Sealing Caps available separately to maintain IP rating of unmated connectors
 - Mate with M12 Series Inline Body and Panel Mount Connectors, depending on part code

// General Information:

Product Display Title:	M12 Series Right-Angle Overmould Flex Body Connectors
Product Family:	Circular Automation Connectors
Product Series:	M12 Series
Body Material:	PVC
Cable Length:	1m
Contact Type:	Socket Contact
Coupling Type:	Screw
Current Max:	4A
Diameter Over Coupling Ring Mm:	20mm
Function:	Right Angle Flex Connector Single Ended Cable
Ip Rating:	IP67
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	5 Contacts
Pin Layout Code:	A Code
Sheath Material:	PVC
Thread Size:	M12 x 1
Voltage Max:	60V

// Product PDF Links

 [M12 Series automation connectors...](#)

// Product 3D CAD Model Links

 [PXPPVC12RAF05ACL010PVC3D CAD Mode](#)