

# ZBM 6 1-10,10-100-BASF 2165352 - Zack marker sheet




1050826

<https://www.phoenixcontact.com/gb/products/1050826>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Zack marker sheet, Sheet, white, labeled, mounting type: latching, for terminal block width: 6.2 mm, Number of individual labels: 100, text field height: 7.5 mm, text field width: 5.6 mm

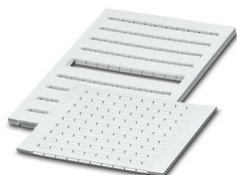

## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 1050826       |
| Packing unit                         | 50 pc         |
| Minimum order quantity               | 50 pc         |
| Sales key                            | BG2123        |
| Product key                          | BG2123        |
| GTIN                                 | 4017918255619 |
| Weight per piece (including packing) | 17.872 g      |
| Weight per piece (excluding packing) | 13.88 g       |
| Customs tariff number                | 49119900      |
| Country of origin                    | PL            |

# ZBM 6 1-10,10-100-BASF 2165352 - Zack marker sheet



1050826

<https://www.phoenixcontact.com/gb/products/1050826>

## Technical data

### Product properties

|              |                         |
|--------------|-------------------------|
| Product type | Labeled terminal marker |
| Pitch        | 6.2 mm                  |
| Type         | high                    |

### Marking

|                                     |     |
|-------------------------------------|-----|
| Number of individual labels         | 100 |
| Number of individual labels per row | 10  |
| Number of marker strips             | 10  |

### Mounting

|               |          |
|---------------|----------|
| Mounting type | latching |
|---------------|----------|

### Material specifications

|                                        |                                |
|----------------------------------------|--------------------------------|
| Color                                  | white (RAL 9010)               |
| Material                               | PA                             |
| Flammability rating according to UL 94 | V2                             |
| Components                             | free from silicone and halogen |

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -40 °C ... 100 °C |
|---------------------------------|-------------------|

### Dimensions

|        |        |
|--------|--------|
| Width  | 5.6 mm |
| Length | 7.5 mm |
| Pitch  | 6.2 mm |

#### Text field

|                   |        |
|-------------------|--------|
| Text field width  | 5.6 mm |
| Text field height | 7.5 mm |

### Standards and regulations

|                 |                             |
|-----------------|-----------------------------|
| Wipe resistance | DIN EN 61010-1 (VDE 0411-1) |
|-----------------|-----------------------------|

# ZBM 6 1-10,10-100-BASF 2165352 - Zack marker sheet



1050826  
<https://www.phoenixcontact.com/gb/products/1050826>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27281101 |
|-------------|----------|

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC000761 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39131500 |
|-------------|----------|

# ZBM 6 1-10,10-100-BASF 2165352 - Zack marker sheet



1050826  
<https://www.phoenixcontact.com/gb/products/1050826>

## Environmental product compliance

|                                         |                            |
|-----------------------------------------|----------------------------|
| EU RoHS                                 |                            |
| Fulfills EU RoHS substance requirements | Yes, No exemptions         |
| EU REACH SVHC                           |                            |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt% |

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd  
Halesfield 13, Telford  
Shropshire, TF7 4PG  
01952 681700  
[info@phoenixcontact.co.uk](mailto:info@phoenixcontact.co.uk)