

Ultra-low-linting chemical protective suit, with breathable microporous laminate.

- **Specialized protection:** With a strong protective barrier*, the AlphaTec® 2000 Ts PLUS SOCO Stitched & Taped - Model 128 resists particulate and liquid biohazards and low-concentration liquid chemicals**
- **Heightened breathability:** Designed with air- and water vapor-permeable microporous laminate fabric, this protective suit is highly breathable, reducing the risk of heat stress in wearers
- **Enhanced fit and features:** An optimal fit delivers excellent comfort, while serged and taped seams and internal overtaped stitching make for a more robust protective barrier, further boosting personal protection
- **Reduced contamination risks:** Combining tunneled, elasticated wrists and ankles with ultra-low-linting material, this chemical-protective suit minimizes the risk of cross contamination in critical areas
- **Decreased surface defect risks:** Being silicone-free, it is perfect for spray-painting applications
- **Assured antistatic properties:** It is also tested against EN 1149-5 antistatic standards

**This protective suit ensures CE Category III Type 4/5/6 protection*

**It withstands liquid chemical saturation and filters 100% of particulates down to 0.01 microns in size (KAKEN particle penetration test)*



Industries

- Defense


Applications

- Crime Scene Investigation (CSI)
- Forensics


KEY FEATURES & BENEFITS

- **Chemical barrier:** Liquid and particulate biohazards, and low-risk liquid chemicals
- **Microporous laminate:** Air- and water vapor-permeable fabric, lower heat stress
- **Optimized fit:** Excellent comfort levels and better workplace safety

Material Diagram

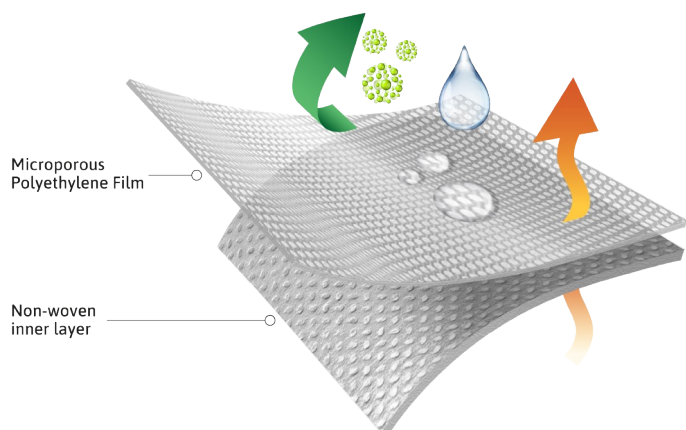

Seam Diagram

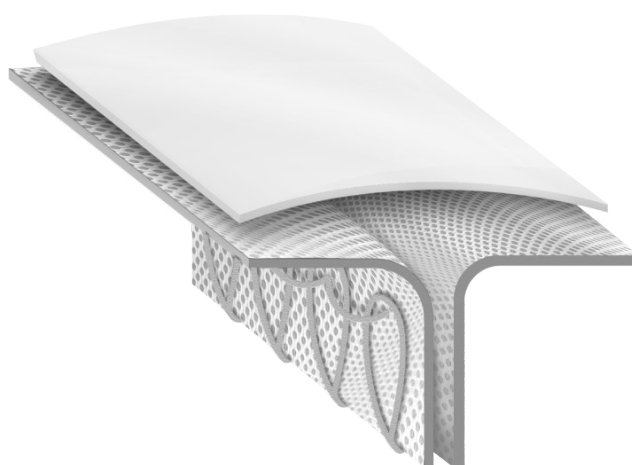

Performance Standards


0598


TYPE 4-B


TYPE 5-B


TYPE 6-B


EN 1073-2


EN 1149-5


EN 14126

EN ISO 13688:2013


DIN 32781

Product Information

Product Information	
Available Sizes	S, M, L, XL, 2XL, 3XL
Color	White
Country Of Origin	China
Packaging Overview	Individually Packed
Product Material	Microporous polyethylene Laminate non-woven
Product Reference	2000 Ts PLUS SOCO - Model 128
Standards Overview	CE CATEGORY III (Type 4-B, Type 5-B, Type 6-B, EN 1073-2, EN 14126, DIN 32781, EN 1149-5)
Seam Type	Stitched and Taped
Shelf Life	5 years
Style Number	W20T128

Suit components & accessories

Suit Components and Accessories	
Design Features	Coverall, 2-piece hood, single front zipper with resealable storm flap, chinstrap, dual finger loops, supplied with 2 pockets. Elasticated hood, wrists, waist and ankles. Blue tape on seams.

For additional in formation visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region
Ansell Healthcare Europe NV
T: +32 (0) 2 528 74 00

North America Region
Ansell Healthcare Products LLC
T: +1 800 800 0444

Australia
Ansell Limited
T: +61 1800 337 041

Asia Pacific Region
Ansell Global Trading Center
T: +603 8310 6688

Latin America & Caribbean Region
Ansell Commercial Mexico S.A. de C.V.
T: +52 442 248 1544 / 248 3133

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending: www.ansell.com/patentmarking © 2025 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

