

Technical data


GS81109

Thrust washer



Needle roller bearing, thrust needle roller bearing, outer ring

VISUAL (S)

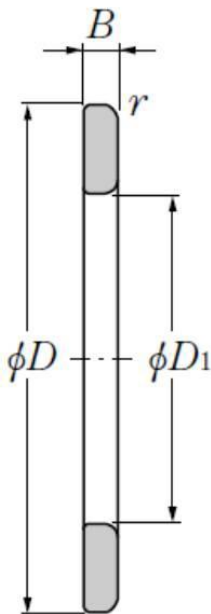

PRODUCT DEFINITION

Brand	NTN
D - Outside diameter of support washer OR - GS	65 mm
D1 - Bore diameter bearing washer OR - GS	47 mm
B - Ring thickness	4 mm
rs - Min fillet radius	0,6 mm
Bearing ring (outer ring) GS mass	0,055 kg

PRODUCT PERFORMANCE

Tmin - Min operating temperature	-20 °C
----------------------------------	--------



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT PERFORMANCE

Tmax - Max operating temperature	120 °C
---	--------

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
------------------	---------

Reference	GS81109
------------------	---------

Image	NRBGS_1.jpg, NRBGS_3.jpg
--------------	--------------------------

