




**ELECTROFLEX flexible conduit with spiral reinforcement**

The ELECTROFLEX tubing is produced with a spiral reinforcement in rigid PVC and is therefore non-metallic. It can be easily cut with a knife or scissors. Very flexible it withstands a very low bending radius. The inside is smooth and allows cable to pass through easily and it can coil around its own diameter without flattening or deforming.

page	type	colour	use	temperature	UL94	
• A7/1-02	normal	black grey	standard	-20 to +60°C	V0	
• A7/1-03	calor	blue	high temperatures	-10 to +90°C	V0	
• A7/1-03	oil	green	oil resistant	-20 to +60°C	V0	

**Cable glands and accessories for ELECTROFLEX flexible conduit**

These self-extinguishing cable-glands, in polypropylene, are made for the ELECTROFLEX flexible conduit and allow a secure connection.

• A7/2-01	Straight conduit-glands ELECTROFLEX	
• A7/2-01	Elbow conduit-glands 90° ELECTROFLEX	


**Pack:**

- tube in reels
- cable glands and accessories in bags

**ELECTROFLEX normal**

**Material:** flexible PVC with hard PVC reinforcement  
**Colours:** black - grey  
**Operating temperature:** -5 to +70°C  
**Protection rating:** IP 65 (with Electroflex cable gland)  
**Flame resistance:** self extinguishing  
**Applications:** flexible conduit for general use.  
**Avantage:** **high flexibility**




type	article number 010	type	article number 013	int.-Ø mm	ext.-Ø mm	 m
150-010	0740 0001 010	155-010	0740 0031 013	10	14,5	30
150-012	0740 0002 010	155-012	0740 0032 013	12	16,5	30
150-016	0740 0003 010	155-016	0740 0033 013	16	21	30
150-022	0740 0004 010	155-022	0740 0034 013	22	27,5	30
150-028	0740 0005 010	155-028	0740 0035 013	28	33,5	30
150-035	0740 0006 010	155-035	0740 0036 013	35	41	30
150-040	0740 0007 010	155-040	0740 0037 013	40	46,4	30
150-050	0740 0008 010	155-050	0740 0038 013	50	57	30


**ELECTROFLEX calor oil**

**Material:** flexible PVC with hard PVC reinforcement  
**Colours:** blue green  
**Operating temperatures:** -20 to +90°C -5 to +70°C  
**Protection rating:** IP 65 (with Electroflex cable gland)  
**Flame resistance:** self extinguishing  
**Application:** protective conduit for use in extreme environments.

**For high temperatures**

**Oil resistant**

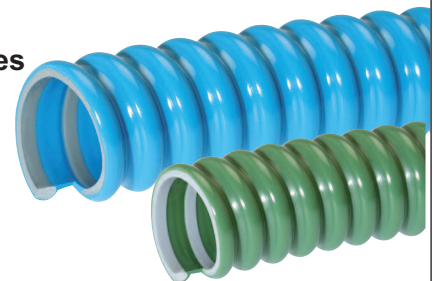

type	article number 002	type	article number 003	int.-Ø mm	ext.-Ø mm	 m
158-010	0740 0021 002	154-010	0740 0011 003	10	14,5	30
158-012	0740 0022 002	154-012	0740 0012 003	12	16,5	30
158-016	0740 0023 002	154-016	0740 0013 003	16	21	30
158-022	0740 0024 002	154-022	0740 0014 003	22	27,5	30
158-028	0740 0025 002	154-028	0740 0015 003	28	33,5	30
158-035	0740 0026 002	154-035	0740 0016 003	35	41	30
158-040	0740 0027 002	154-040	0740 0017 003	40	46,4	30
158-050	0740 0028 002	154-050	0740 0018 003	50	57	30

 A7/2 ELECTROFLEX cable glands

