

Datasheet

RS Pro Fuse Holder, For 5 x 20 mm Fuse

Stock No: 1884480,1884637




Specifications:

Materials

- Body : Phenolic Molding Compound
- Cover : Polybutylene Terephthalate
- Nickel or tin plated copper alloy

Drawing (mm):

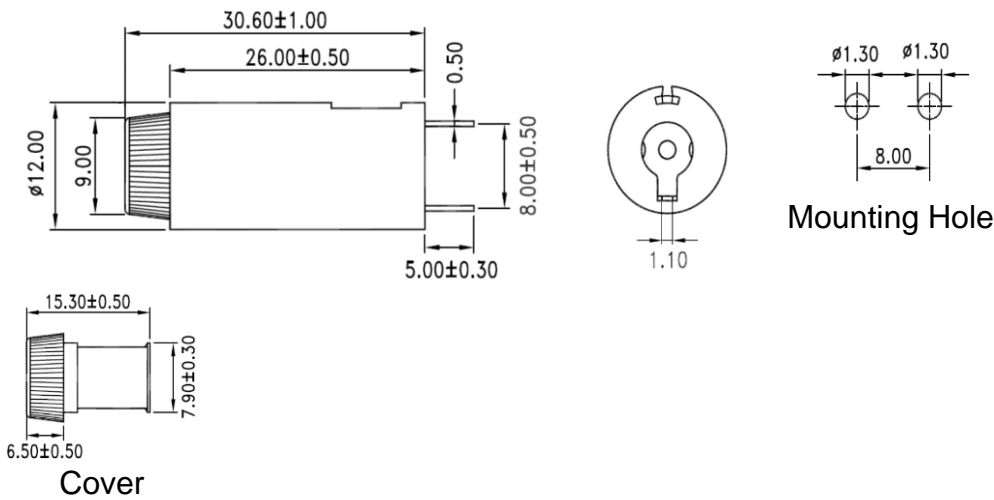

Tolerance : ±0.2



ENGLISH

Electrical Characteristic:

Rated Current : 10A 250V.

Insulation Resistance : 100M Ω Min (at 500V DC).

Contact Resistance : 5m Ω (at 1A DC).

Dielectric Strength For 60 Seconds : AC 1000V Min.

Insulating Body : Flame retarding UL 94 V0 thermoplastic material.

Reference:

Stock No	Rating amperes
1884480	10A 250V
1884637	10A 250V