


vacuum suction cup

ESV-50-BU

Part number: 191064

FESTO

Wearing part, easily replaceable

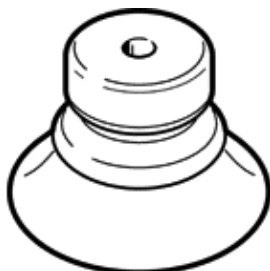

Data sheet

Feature	Value
Suction cup height compensator	11 mm
Min. workpiece radius	150 mm
suction cup diameter	50 mm
suction cup volume	14.23 cm ³
Position of connection	on top
Assembly position	Any
Suction cup shape	Round, bellows 1.5 conv
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:]
Food-safe	See Supplementary material information
Ambient temperature	-20 ... 60 °C
Retention force at nominal operating pressure	72.6 N
Product weight	13.9 g
Colour	blue
Shore hardness	60 +/- 5
Materials note	Free of copper and PTFE Contains PWIS substances Conforms to RoHS
Material suction cup	PUR