


Datasheet

Flat 2-part spring probe, 2.54mm pitch

RS Stock number [261-5109](#)

Dimensions (mm)

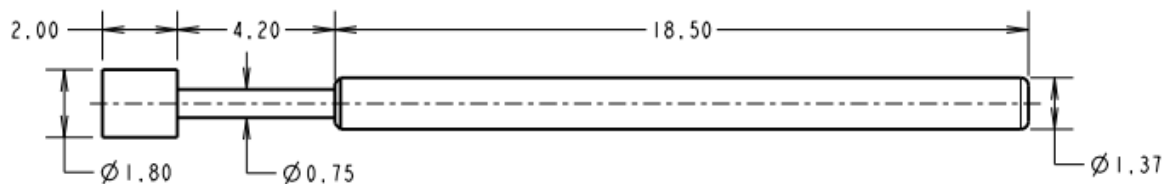

Specifications

Electrical

- Current Rating: 3A
- Contact Resistance: 30 Milliohms

Materials

- Plunger: Heat treated Beryllium Copper
- Barrel: Phosphor Gold
- Spring: Steel
- Finish
- Plunger and Barrel: Gold

Mechanical

- Durability: 100,000 cycles
- Full Travel: 4.20mm
- **Environmental**
- Operating temperature range: -40° C to +85° C