


# Telescopic drywall supports

## Extends with power



- Resilient up to a maximum of 350 kg
- when the telescopic rod is fully retracted
- Extremely stable construction due to
- highly durable steel pipes and non-slip
- PVC contact surfaces (9 x 7 cm)
- Single-handed operation thanks to
- 2-component plastic handle with pump mechanism
- Quick-slide button for rapid extension
- and retraction of the telescopic bar
- Controllable holding force by turning the support on the grip
- Application also on slopes due to continuously swivelling contact surfaces from -45° to +45°
- STE250, STE300, STE370: GS-certified

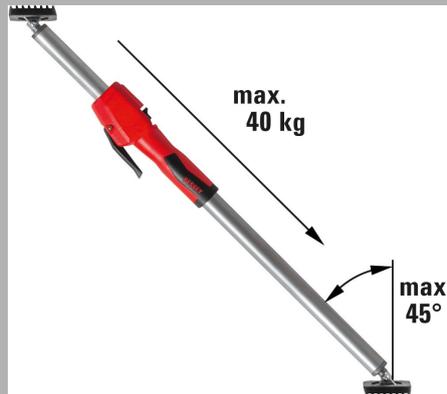

Telescopic drywall support STE with pump grip

No.	Adjusting range	Load limit at		Scales
		min. extension length	max. extension length	
	mm	kg	kg	kg
STE90	575-910	350	350	1.80
STE250	1450-2500	350	160	3.30
STE300	1700-3000	350	110	3.80
STE370	2070-3700	350	65	4.50

