


## Plug StarTOP® with SafeCONTACT - Part no. 953



- screwless, with insulating displacing technique
- cable gland and sealing
- strain relief and protection against kinking
- enclosure with thread lock and safety slide

|                       |                         |
|-----------------------|-------------------------|
| Protection type       | IP 44                   |
| Ampere                | 16 A                    |
| Poles                 | 4p                      |
| Voltage               | 500                     |
| Hertz                 | 50-60Hz                 |
| Earth position        | 7h                      |
| Contact               | standard                |
| Connection technology | Screwless - SafeCONTACT |

Std. Pack. 10 Qty.

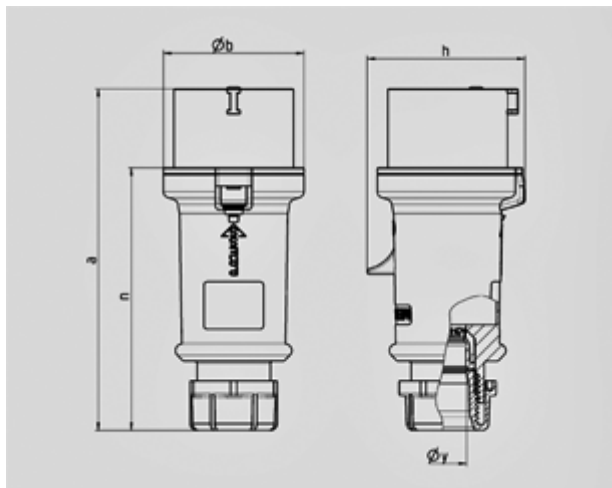

| Drawing                  | Amp.  | 16   |       |       | 32   |      |     |
|--------------------------|-------|------|-------|-------|------|------|-----|
|                          |       | 3    | 4     | 5     | 3    | 4    | 5   |
| 2 MB 214                 | Poles |      |       |       |      |      |     |
| Dim. in mm               | a     | 148  | 160   | 160   | 197  | 197  | 197 |
|                          | b     | 55   | 65,6  | 65,6  | 75   | 75   | 75  |
|                          | h     | 61   | 72,5  | 72,5  | 80,5 | 80,5 | 85  |
|                          | n     | 112  | 123,5 | 123,5 | 152  | 152  | 152 |
|                          | y     | 14,5 | 16    | 16    | 22   | 22   | 22  |
| Terminal for cond. cross |       | 1    | 1     | 1     | 2,5  | 2,5  | 2,5 |
| section (mm²) min.-max.  |       | —2,5 | —2,5  | —2,5  | —6   | —6   | —6  |