

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [503474-0200](#)
Status: **Active**
Overview: Flexi-Mate™ Connector System
Description: Flexi-Mate™ 3.70mm Pitch Receptacle Circuit Terminator Connector, Right Angle, 3.00mm Stacking Height, 2 Circuits

Documents:

[3D Model](#) [Application Specification AS-503471-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-503471-001 \(PDF\)](#)

Agency Certification

UL E29179

General

Product Family Accessories
 Series [503474](#)
 Component Type Circuit Terminator
 Overview [Flexi-Mate™ Connector System](#)
 Product Name Flexi-Mate™
 UPC 883906918651

Physical

Circuits (Loaded) 2
 Color - Resin White
 Flammability 94HB
 Gender Receptacle
 Lock to Mating Part Yes
 Material - Metal Phosphor Bronze
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Net Weight 233.680/mg
 Packaging Type Bag
 Polarized to Mating Part Yes
 Temperature Range - Operating -40°C to +85°C
 Termination Interface: Style N/A


Electrical

Current - Maximum per Contact 2A

Material Info

Reference - Drawing Numbers

Application Specification AS-503471-001
 Product Specification PS-503471-001, RPS-503471-002, RPS-503471-007, RPS-503474-001, RPS-503474-002
 Sales Drawing SD-503474-001

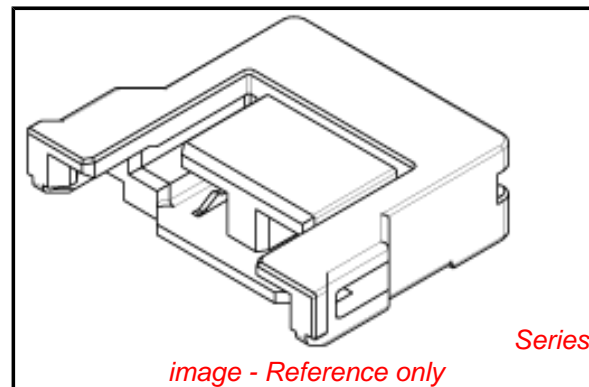

EU RoHS

ELV and RoHS Compliant
REACH SVHC Contains SVHC: No
Low-Halogen Status Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[503474Series](#)

Use With

[503469 PCB Header](#)