


KEMET Part Number: ALP22A101BB450 **Not for New Design**
(A622DG101M450A)

ALP22, Aluminum Electrolytic, 100 uF, 20%, 450 VDC, -40/+85°C

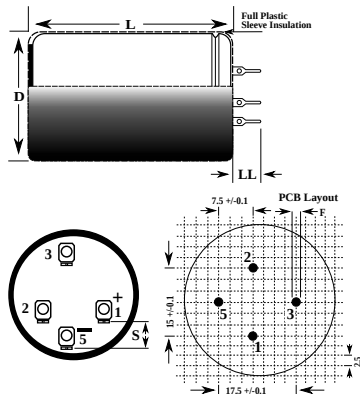

General Information	
Supplier:	KEMET
Series:	ALP22
Dielectric:	Aluminum Electrolytic
Description:	Solder Pin, Aluminum Electrolytic
Features:	Solder Pin
RoHS:	Yes
Lead:	4 Pin Solder
AEC-Q200:	No
Notes:	Dimensions D And L Include Slewing

Dimensions	
D	30mm +/-1mm
L	45mm +/-2mm
S	7.5mm +/-0.1mm
LL	7.5mm +/-0.5mm
F	1.3mm

Specifications	
Capacitance:	100 uF
Capacitance Tolerance:	20%
Voltage DC:	450 VDC, 495 VDC (Surge)
Temperature Range:	-40/+85°C
Rated Temperature:	85°C
Life:	15000 Hrs
Leakage Current:	270 uA (5min 20°C)

Packaging Specifications	
Weight:	50 g
Slewing:	Yes
Packaging:	Bulk, Bag