


Cannon

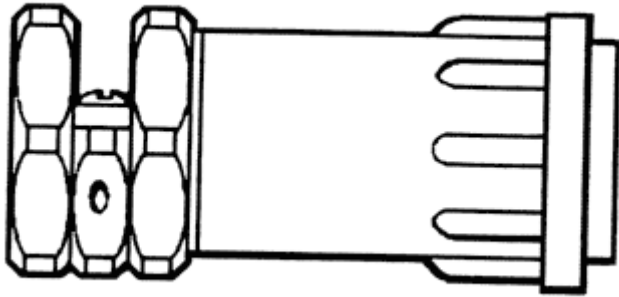

<b>PartNumber</b>	192900-0496
<b>Product Family</b>	European Circular
<b>Product Group</b>	KPTC-NG
<b>Product Type</b>	Accessory
<b>Veff Test Voltage at Sea Level Service Class 1</b>	1500
<b>Veff Test Voltage at Sea Level Service Class 2</b>	2300
<b>Veff Test Voltage at 21336 m Service Class 1</b>	375
<b>Veff Test Voltage at 21336 m Service Class 2</b>	550
<b>Minimum Cable Accommodation, Outer Sheath Diameter</b>	Ø6,90 (.272)
<b>Accessory Type</b>	Endbell
<b>Shielded</b>	No
<b>Dimension A</b>	57,00 (2.441)
<b>Dimension B</b>	Ø11,30 (.449)
<b>Dimension C</b>	Ø24,00 (.945)

<b>Dimension D</b>	19,00 (.748)
<b>Nomenclature</b>	TNA14CCHC-00L
<b>Sealed</b>	Yes
<b>Shell Size</b>	14
<b>Maximum Cable Accommodation, Outer Sheath Diameter</b>	Ø10,20 (.402)
<b>Note 2</b>	Contacts are sold separately.
<b>V= Test Voltage at Sea Level Service Class 1</b>	2100
<b>V= Test Voltage at Sea Level Service Class 2</b>	3200
<b>V= Test Voltage at 21336 m Service Class 1</b>	535
<b>V= Test Voltage at 21336 m Service Class 2</b>	770
<b>Footnote</b>	Dimensions are in mm (inch). Dimensions are subject to change.
<b>For more information</b>	Contact Cannon Sales Dept.