

# 95 62 160

## Wire Rope Cutter Also for high-strength wire rope



- Compact, light and powerful
- Up to 30 % less physical effort compared to wire rope cutters of the same length
- Double-mounted box joint design for high level of stability
- Cutting edges additionally induction hardened, cutting edge hardness approx. 64 HRC
- Convenient work thanks to opening spring
- Secured by locking device during transport
- Ball bearing steel



- For wire rope with Ø 4.00 / 1960 Nmm<sup>2</sup>


<b>Article No.</b>	95 62 160
<b>EAN</b>	4003773082354
<b>Head</b>	
<b>Tool</b>	burnished
<b>Handles</b>	with multi-component grips
<b>Cutting capacity copper cable, multiple-stranded (diameter) Ø mm</b>	6,0
<b>Cutting capacities wire rope (diameter) Ø mm</b>	4,0
<b>Length mm</b>	160
<b>Net weight g</b>	170



Compact at 160 mm but nevertheless more powerful than many larger wire rope cutters



For cutting high-strength wire ropes (1960 N/mm<sup>2</sup>) with a diameter of up to 4 mm

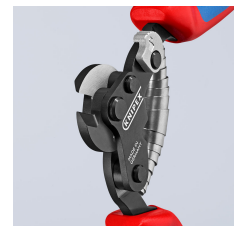

Double-bearing joint

*technical change and errors excepted*