


Features

- Thermoresistance
- Max. operating temperature 200°C
- Protection tube AISI304 (DIN1.4301)
- Silicone + Silicone
- Immersion Length 40mm
- Tube Diameter 6mm
- Cable Length 1,5m

RS PRO Bayonet Type PTC Thermoresistance Temperature Sensor

RS Stock No: 0350379

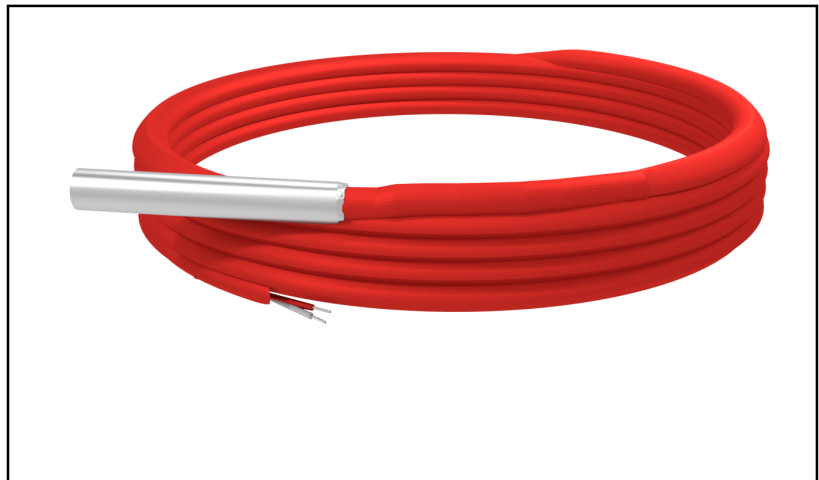

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Bayonet Bore Type PTC Thermoresistance Temperature Sensor

Diameter(M): 6mm

Immersion Length(L): 40mm

Cable Length(K): 1,5m

Applications Fields

- Panel Manufacturing
- Production and Test Equipment
- Food, Chemical, Textile Sectors
- Industrial Control Applications


General Specifications

Max. Operating Temperature	-50 °C / +200 °C
Standard cable types	Silicone + Silicone
Sensor type	PTC-1K
Protection tube material	AISI304 (DIN1.4301) Standard production

Mechanical Specifications

Diameter (M)	6mm
Immersion Length (L)	40mm
Cable Length (K)	1,5m

Electrical Connection

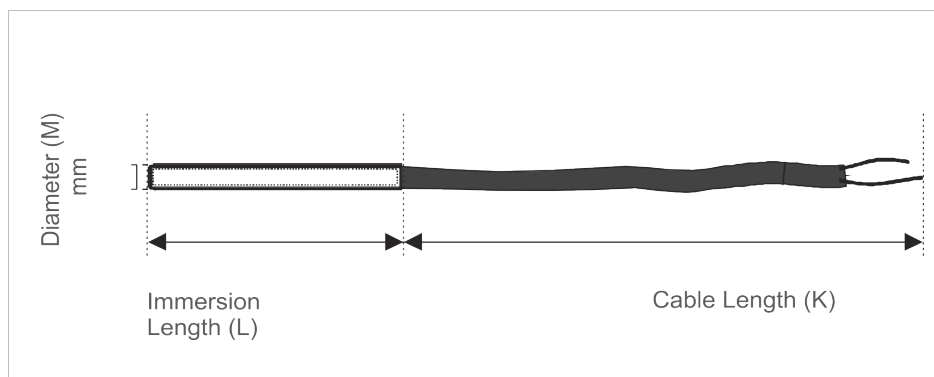

PTC Connections

