

SAC-3P-MS/0,8-240/A SCO J-YM - Sensor/actuator cable

1410060
<https://www.phoenixcontact.com/gb/products/1410060>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sensor/actuator cable, 3-position, PUR halogen-free, yellow, Plug straight M12 SPEEDCON, coding: A, on Valve connector A, cable length: 0.8 m, Customer version

Commercial data

Item number	1410060
Packing unit	1 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Sales key	AF1DDA
Product key	AF1DDA
GTIN	4046356888684
Weight per piece (including packing)	60.3 g
Weight per piece (excluding packing)	60.3 g
Customs tariff number	85444290
Country of origin	PL

SAC-3P-MS/0,8-240/A SCO J-YM - Sensor/actuator cable



1410060

<https://www.phoenixcontact.com/gb/products/1410060>

Technical data

Product properties

Product type	Sensor/actuator cable with valve connector
Number of positions	3
No. of cable outlets	1
Shielded	no
Coding	A

Insulation characteristics

Overvoltage category	III
Degree of pollution	3

Material specifications

Flammability rating according to UL 94	HB
Seal material	TPU
Material housing valve plug	TPU
Material of grip body	TPU
Contact material	CuSn
Contact surface material	Ni/Au
Contact carrier material	TPU GF
Contact material	CuSn
Valve plug contact insert material	PA 6.6
Contact surface material	Sn
Material for screw connection	Zinc die-cast, nickel-plated

Electrical properties

Insulation resistance	$\geq 100 \text{ M}\Omega$
Nominal voltage U_N	48 V AC
	60 V DC
Nominal current I_N	4 A

Connector

Connection 1

Type	Plug straight M12 SPEEDCON
Number of positions	3
Locking type	SPEEDCON
Coding type	A

Connection 2

Type	Valve connector A
Material	CuSn (Contact)
	Sn (Contact surface)
	PA 6.6 (Contact carriers)

SAC-3P-MS/0,8-240/A SCO J-YM - Sensor/actuator cable



1410060


<https://www.phoenixcontact.com/gb/products/1410060>

	TPU (Housing)
--	---------------

Cable/line

Cable length	0.8 m
--------------	-------

PUR halogen-free yellow [240]

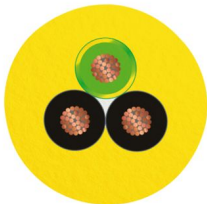Dimensional drawing	
Cable weight	30 kg/km
UL AWM Style	20549 (80°C/300 V)
Number of positions	3
Shielded	no
Cable type	PUR halogen-free yellow [240]
Conductor structure signal line	28x 0.15 mm
AWG signal line	20
Conductor cross section	3x 0.5 mm²
Wire diameter incl. insulation	1.46 mm ±0.02 mm
External cable diameter	4.50 mm ±0.15 mm
Outer sheath, material	PUR
External sheath, color	yellow
Conductor material	Bare Cu litz wires
Material wire insulation	PP
Single wire, color	black 1, black 2, green/yellow
Thickness, insulation	≥ 0.21 mm
Thickness, outer sheath	approx. 0.60 mm
Overall twist	3 wires, twisted
Max. conductor resistance	≤ 39 Ω/km
Insulation resistance	≥ 10 GΩ*km
Nominal voltage, cable	≤ 300 V
Test voltage	≥ 3000 V
Minimum bending radius, fixed installation	5 x D
Minimum bending radius, flexible installation	10 x D
Smallest bending radius, fixed installation	23 mm
Smallest bending radius, movable installation	45 mm
Halogen-free	in accordance with DIN VDE 0472 part 815
Flame resistance	in accordance with DIN UL-Style 20549
Resistance to oil	in accordance with DIN EN 60811-2-1
Ambient temperature (operation)	-15 °C ... 80 °C (cable, fixed installation)

1410060
<https://www.phoenixcontact.com/gb/products/1410060>

Environmental and real-life conditions

Ambient conditions	
Degree of protection	IP65
	IP67
Ambient temperature (operation)	-25 °C ... 90 °C (Plug / socket)
	-20 °C ... 85 °C (Valve connector)
	-40 °C ... 80 °C (cable, fixed installation)
	-15 °C ... 80 °C (Cable, flexible installation)

SAC-3P-MS/0,8-240/A SCO J-YM - Sensor/actuator cable

1410060

<https://www.phoenixcontact.com/gb/products/1410060>


Drawings

Dimensional drawing



Plug, M12 x 1, straight, shielded

Dimensional drawing

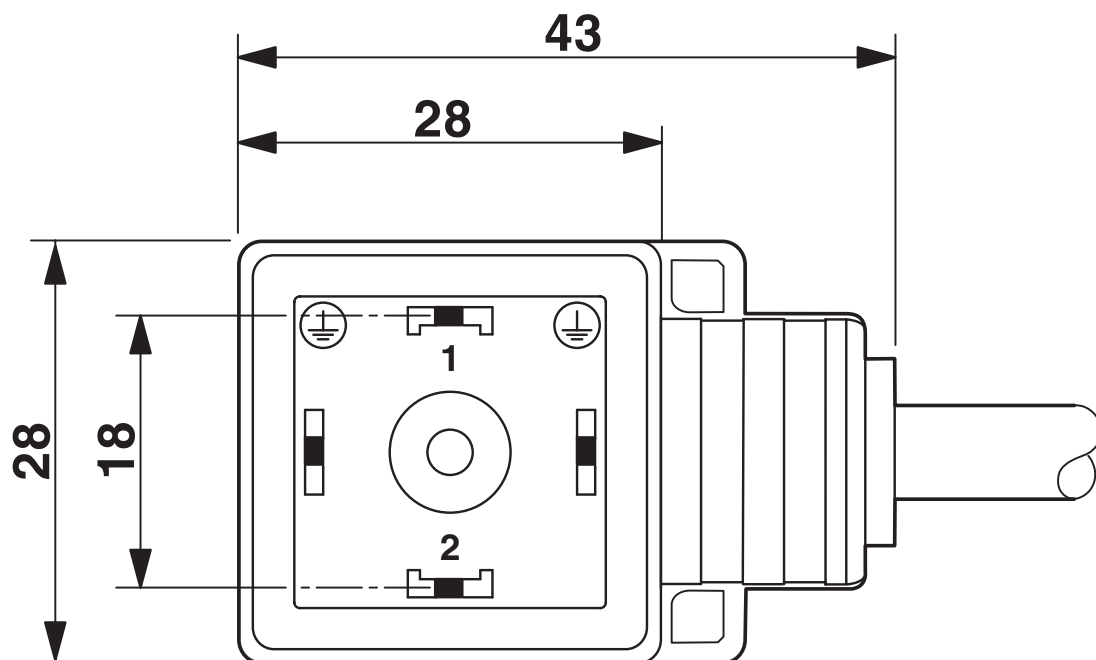


Valve connector, type A


SAC-3P-MS/0,8-240/A SCO J-YM - Sensor/actuator cable

1410060

<https://www.phoenixcontact.com/gb/products/1410060>

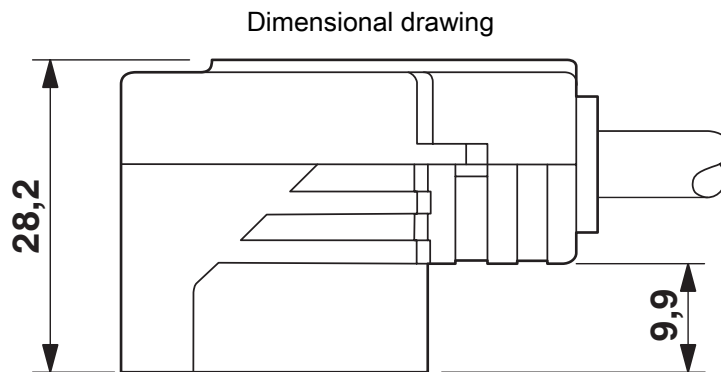

Valve connector, type A, side view

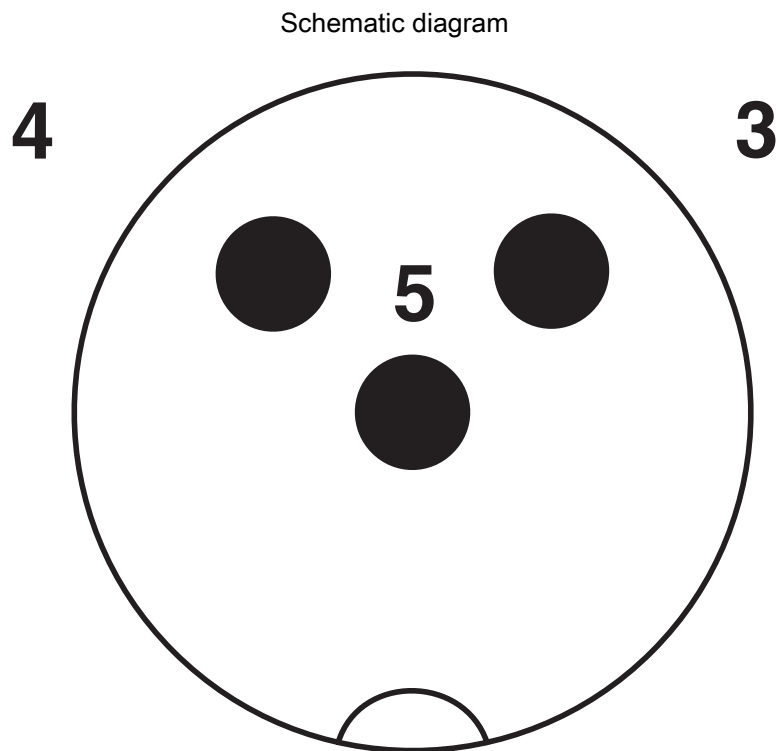


Pin assignment M12 plug, 3-pos., valve connector

SAC-3P-MS/0,8-240/A SCO J-YM - Sensor/actuator cable

1410060

<https://www.phoenixcontact.com/gb/products/1410060>

Schematic diagram

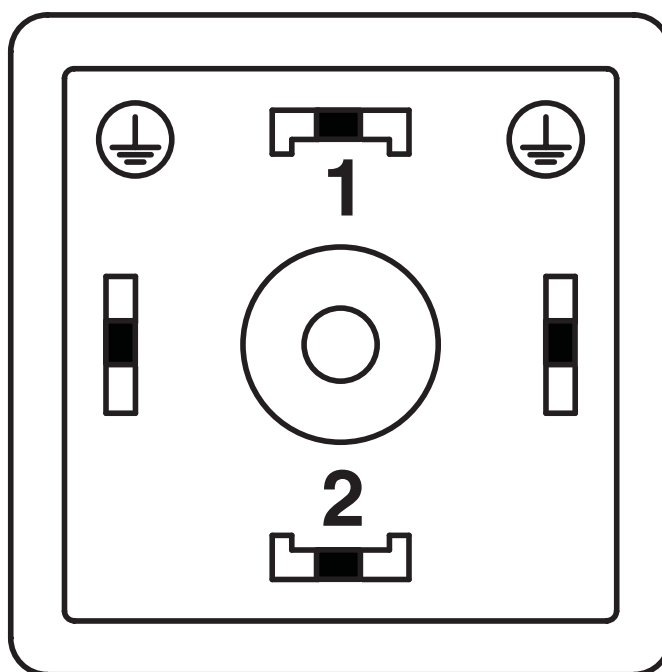

Valve connector pin assignment, type A

SAC-3P-MS/0,8-240/A SCO J-YM - Sensor/actuator cable



1410060
<https://www.phoenixcontact.com/gb/products/1410060>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/gb/products/1410060>

 CSAus Approval ID: 13631	Nominal voltage U_N	Nominal current I_N	Cross section AWG	Cross section mm^2
	60 V	4 A	-	-

SAC-3P-MS/0,8-240/A SCO J-YM - Sensor/actuator cable



1410060
<https://www.phoenixcontact.com/gb/products/1410060>

Classifications

ECLASS

ECLASS-13.0	27060312
-------------	----------

ETIM

ETIM 9.0	EC001855
----------	----------

UNSPSC

UNSPSC 21.0	31251500
-------------	----------

1410060
<https://www.phoenixcontact.com/gb/products/1410060>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT Ltd
Halesfield 13, Telford
Shropshire, TF7 4PG
01952 681700
info@phoenixcontact.co.uk