

**Professionally approved products.**  
**Datasheet**  
**Connecting Tubes**



## Specifications

- **Material**

AISI 304 stainless steel.

Bar for  $d = 8$  and  $10$ .

Tube for  $d = 12, 16$  and  $20$ .


- **Standard executions**

- **MSM-T-SST**: without graduations.

- **MSM-T-SST-CS**: with laser engraved precision graduations (mm).

## Professionally approved products. Datasheet

MSM-T-SST

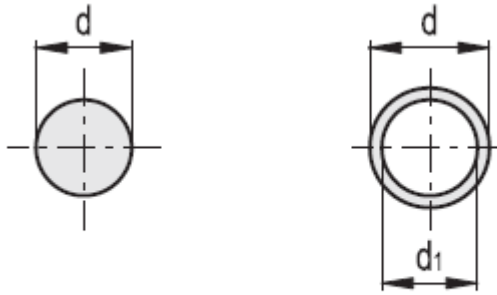

Main Dimensions				
Stock No.	$d_1$	$l$	$d_1$	$l_1$
7866006	8	100	-	15
7866040	10	200	-	15
7866059	10	300	-	15
7866084	12	200	9	15
7866093	12	300	9	15
7866153	16	200	13	20
7866157	16	300	13	20
7866188	20	150	16	25
7866181	20	300	16	25