


40B.JP12 – 12 Piece Slim Wrenches Set

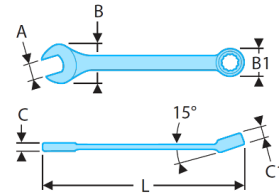

Description:

- **12-Point OGV® Profile** – Maximising the contact surface with the nut.
- Matte finish
- **Ring-end angled at 15°**– Prevents fingers from coming into contact with nearby surfaces, offering safe and comfortable use.
- **Open-end angled at 15°** – Reduced recovery angle for increased accessibility.
- **ISO 691, ISO 1711-1, ISO 3318, ISO 7738, DIN 3113**
- **SET Contains** – 8,9,10,11,12,13,14,15,16,17,18 and 19mm wrenches

	A (mm)	B (mm)	B1 (mm)	C (mm)	C1 (mm)	L (mm)
40B.8	8	20.2	13.2	4	5	120
40B.9	9	22.2	14.6	4	6	130
40B.10	10	23.7	16	4	6.5	140
40B.11	11	25.7	17	4.7	6.5	150
40B.12	12	27.5	19	4.8	7	160
40B.13	13	28.7	20.6	5.5	7.5	170
40B.14	14	31.7	22	5.6	8	180
40B.15	15	34	23.4	5.7	8.5	190
40B.16	16	36	24.8	5.8	9	200
40B.17	17	38.5	26.2	6.3	9.5	210
40B.18	18	39	27.6	6.8	10	220
40B.19	19	42.2	29	7.1	10.4	230