

DISCONNECT MOUNTING SPACE


Disconnects will occupy space on panel shown by dimensions E1, F1 and G1 in Disconnect Mounting Space diagram. Wiring space W1 is available when disconnect is installed in the enclosure.

- E1 = 4.75 in. (121 mm) when C = 8.00 in. (203 mm)
- E1 = 7.09 in. (180 mm) when C = 10.00 in. (254 mm)
- E1 = 11.62 in. (294 mm) when C = 12.00 in. (305 mm)
- E1 = 11.62 in. (294 mm) when C = 16.00 in. (406 mm)
- E1 = 18.38 in. (467 mm) for A60SA3812A24LP
- W1 = Wiring Space.

See *Technical Information for wire bend space.*

Refer to **NATIONAL ELECTRICAL CODE 2005** article 430.10(B) for wiring space required for line side conductors to be connected to disconnect.

Verify your application to determine if wiring space is adequate.

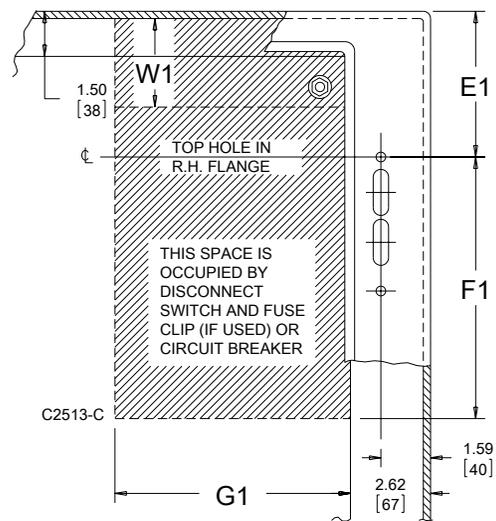


Consult disconnect manufacturer or see Disconnect Ordering information at hoffmanonline.com under Technical Resources for F1 and G1 dimensions of various brands of disconnects.

PANELS FOR A26 LOW-PROFILE TYPE 12 DISCONNECT ENCLOSURES

Optional panels for low-profile Type 12 enclosures (Bulletin A26) are .121-in. steel. Finish is white polyester powder paint or a conductive, corrosion-resistant coating. Mounting hardware included with enclosure.

BULLETIN: A26P

Catalog Number	AxB in.	AxB mm	Finish	Panel Size D x E (in.)	Panel Size D x E (mm)	Fits Bay
A25P21	25.88 x 21.75	657 x 552	Painted steel	25.88 x 21.75	657 x 552	1
A31P21	31.88 x 21.75	810 x 552	Painted steel	31.88 x 21.75	810 x 552	1
A31P21G	0.00		Conductive	31.88 x 21.75	810 x 552	1
A37P21	37.88 x 21.75	962 x 552	Painted steel	37.88 x 21.75	962 x 552	1
A37P21G	37.88 x 21.75	962 x 552	Conductive	37.88 x 21.75	962 x 552	1
A42P33	42.88 x 33.75	1089 x 857	Painted steel	42.88 x 33.75	1089 x 857	1
A42P33G	0.00		Conductive	42.88 x 33.75	1089 x 857	1
A54P33	54.88 x 33.75	1394 x 857	Painted steel	54.88 x 33.75	1394 x 857	1
A54P33G	0.00		Conductive	54.88 x 33.75	1394 x 857	1
A25P48	25.88 x 48.00	657 x 1219	Painted steel	25.88 x 48.00	657 x 1219	2
A25P48G	0.00		Conductive	25.88 x 48.00	657 x 1219	2
A31P48	31.88 x 48.00	810 x 1219	Painted steel	31.88 x 48.00	810 x 1219	2
A31P48G	0.00		Conductive	31.88 x 48.00	810 x 1219	2
A37P48	37.88 x 48.00	962 x 1219	Painted steel	37.88 x 48.00	962 x 1219	2
A37P48G	0.00		Conductive	37.88 x 48.00	962 x 1219	2
A42P72	42.88 x 72.00	1089 x 1829	Painted steel	42.88 x 72.00	1089 x 1829	2
A42P72G	0.00		Conductive	42.88 x 72.00	1089 x 1829	2
A54P72	54.88 x 72.00	1394 x 1829	Painted steel	54.88 x 72.00	1394 x 1829	2
A54P72G	0.00		Conductive	54.88 x 72.00	1394 x 1829	2

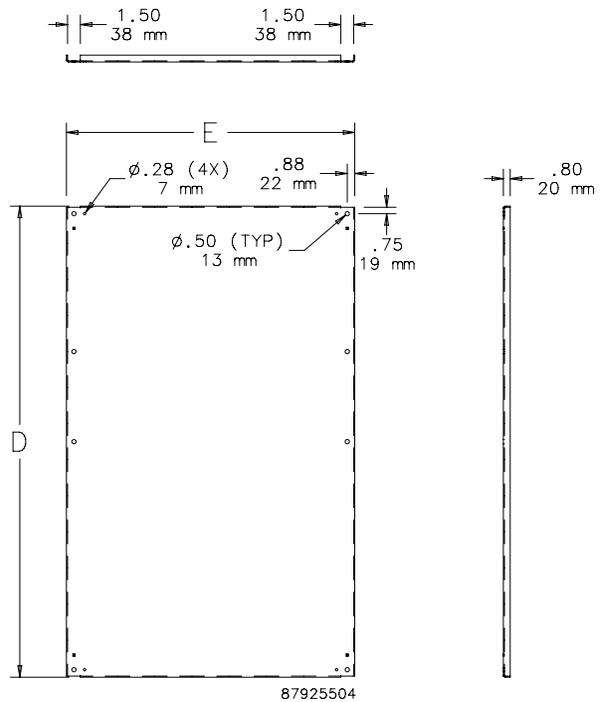

87925504