

LEDVANCE® Downlight 14W

Indoor luminaires | LED downlight | Ceiling cut-out: 150mm



Area of application

- General illumination
- Public areas
- Stairways
- Corridors
- Foyers
- Shops


Product benefits

- Direct replacement for conventional 2x18W CFL downlights
- Design matches the LEDVANCE SPOT luminaire family
- Energy savings up to 60% (compared to 2x18W CFL luminaires)
- Very homogenous light
- Functional design
- Easy installation with fast connection
- External driver for extended flexibility (compatible with recommended DALI drivers)
- Available certificates: CE, CB, TUEV SUED

Product features

- Luminaire efficacy: up to 95 lm/W
- Luminous flux: up to 1360lm
- Diameter of required ceiling cut-out: 150mm
- Available with colour temperature: 3000K, 4000K, 6500K
- Beam angle: 95°
- Type of protection: IP20
- White Aluminum housing, PMMA diffuser
- Ambient operating temperature: -20...+45 °C
- Lifetime (L70/B50): up to 30000h
- 3-years guarantee

Technical data

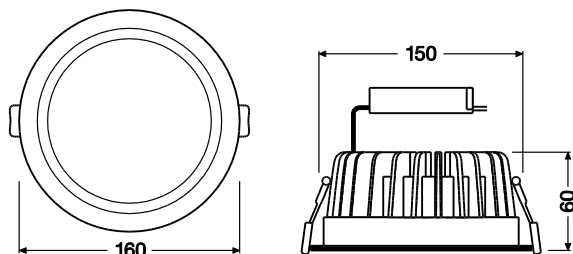

Product description	GTIN (EAN)	Nominal wattage [W]	Nominal voltage [V]	Power factor [λ]	Luminous flux [lm]	Luminaire efficacy [lm/W]	Colour temperature [K]	CRI index [Ra]
Downlight LED 14W/3000K 230V IP20	4058075000001	14W	230V	> 0.9	1310	90	3000K	>80
Downlight LED 14W/4000K 230V IP20	4058075000025	14W	230V	> 0.9	1360	95	4000K	>80
Downlight LED 14W/6500K 230V IP20	4058075000049	14W	230V	> 0.9	1360	95	6500K	>80

Product description	Beam angle	Rated life time L70 / B50 [h]	Type of protection IP rating	Protection class	Product size l x w or Ø [mm]	Height h [mm]	Body colour
Downlight LED 14W/3000K 230V IP20	95°	30000	20	II	Ø160	60	white
Downlight LED 14W/4000K 230V IP20	95°	30000	20	II	Ø160	60	white
Downlight LED 14W/6500K 230V IP20	95°	30000	20	II	Ø160	60	white

Packaging information

Product description	GTIN (EAN)	Dimensions EAN10 l x w x h [mm]	Gross weight EAN 10 [g]	Volume [dm³]	Packaging unit [Pieces/unit]
Downlight LED 14W/3000K 230V IP20	4058075000001	175 x 175 x 105	774	3.87	18
Downlight LED 14W/4000K 230V IP20	4058075000025	175 x 175 x 105	774	3.87	18
Downlight LED 14W/6500K 230V IP20	4058075000049	175 x 175 x 105	774	3.87	18

Recommended DALI drivers (not included)

Product description	GTIN (EAN)	Nominal Wattage [W]	Voltage in [V AC]	Voltage out [V DC]	Current out [mA DC]	Driver EAN10	Driver product description
Downlight LED 14W/3000K 230V IP20	4058075000001	14W	200-240V	27-42V	350	4052899324879	OTI DALI 15/220...240/1A0 LT2
Downlight LED 14W/4000K 230V IP20	4058075000025	14W	200-240V	27-42V	350	4052899324879	OTI DALI 15/220...240/1A0 LT2
Downlight LED 14W/6500K 230V IP20	4058075000049	14W	200-240V	27-42V	350	4052899324879	OTI DALI 15/220...240/1A0 LT2

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.