




FAG

SES512-610-L [↗](#)

Plummer block housing




Split plummer block housing for various bearing designs. The SNV series will be replaced by the new SES series in 2022.

Technical information

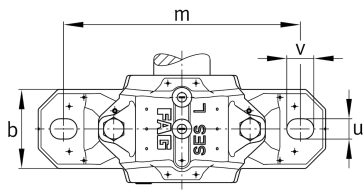

Main Dimensions & Performance Data

D	110 mm	Outside diameter bearing
a	255 mm	Length base
h ₁	134 mm	Height
g	105 mm	Width housing body
K	48 mm	Width bearing seat
≈m	5.2 kg	Weight

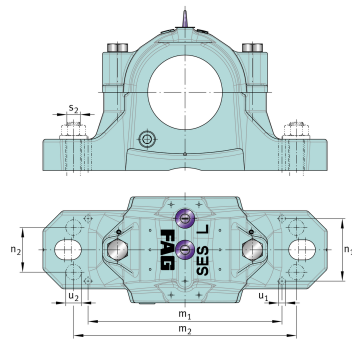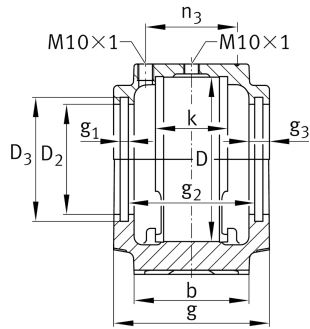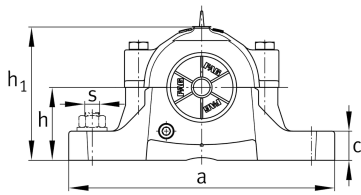

Dimensions

b	70 mm	Width base
c	30 mm	Height base
h	70 mm	Base to shaft centerline height
m	210 mm	Distance fixing bore
s	15.875 mm	Screw size
s	M16	Size of fixing screws
u	18 mm	Width slot
v	24 mm	Length slot
D 2	72 mm	Diameter sealing
D 3	80.5 mm	Diameter sealing groove
D 5	78.2 mm	Outside diameter sealing labyrinth
g 1	5 mm	Width sealing groove
g 2	87 mm	Distance sealing
g 3	12 mm	Wall thickness
g 4	37 mm	Distance oil lubrication
m 1	174 mm	Distance holes aligned pins m1
n 3	62 mm	Distance lubrication
n 4	90 mm	Distance lubrication sealing
u 1	6 mm	Bore diameter u1
u 2	14 mm	Bore diameter u2