




Hand Lamp E27 60W 230V IP44 5M cable

Article number: 146587

BAI Hand Lamp 60W E27 230V IP44 CLII Black 5m connection cable HN05R-F 2G1.0mm² with plug 96x280mm

This classic portable hand lamp is both handy and robust – and becomes energy-efficient when fitted with an E27 LED bulb. It comes with a 5-meter power cable, offering flexibility where you need it most. The protective metal grid and glass shield ensure the light source is well protected. Designed for tough jobs, but equally at home in vintage or industrial-style interiors.

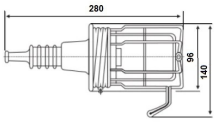

General ETIM properties

ETIM group	Luminaires
ETIM class	Hand luminaire
Name	Hand Lamp E27 60W 230V IP44 5M cable
Brand	Bailey
Productseries	Hand lamp
Producttype	E27

ETIM specifications

Lamp type	Incandescent lamp
With light source	No
Suitable for number of light sources	1
Max. system power [W]	60
Degree of protection (IP)	IP44
With connection cord and plug	Yes
With switch	No
With suspension hooks	Yes
Nominal voltage [V]	230 - 230
Diameter [mm]	96
With protective cover	Yes
Voltage type	AC/DC
With CEE-plug	Yes
Protection class according to IEC 61140	II
Suitable for lamp power [W]	60 - 60
Height/depth [mm]	280
Cable length [m]	5
Automatic cable winding	No
Energy efficiency class of the light source according to EU regulation 2019/2015	Not required
With holder	Yes
With charging station	No

Complementary articles



145630
LED Industry A60 E27 9.5W
(83W) 1200lm 840 100V-260V
AC/DC



146576
LED Industry A60 E27 8W (66W)
900lm 830 100V-260V AC/DC