

特点

- 柔性 Durable 电缆、带 pvc 护套
- 完全模制连接器、确保强度和耐用性
- 可靠的集成应力消除、用于连接支持和保护
- BS D
- 直角 10 a iec C13 插座

RS 2m Pro 电源电缆、 C13 、 iec 到英式插头、 10 a 、 250 v

RS 号: 426-395



RS 认证产品为您提供所有产品类别的专业品质部件。我们的产品系列经过工程师测试、提供与领先品牌相当的质量、而无需支付高昂的价格。

产品说明

RS PRO 的高品质耐用电源线组件或电源线，用于将设备连接到主电源。这款电源线一端完全配备 UK BS1363 3 引脚电源插头，另一端的 IEC C13 型连接器可连接至设备。电源线具有集成的应力消除装置，可为连接器提供额外的保护和支撑，并防止因过度弯曲而造成的损坏

一般规格

连接器 a	C13, IEC
接头 b	英式插头
护套颜色	白色
连接器 a 型	cee 7/7.
电源插头类型	g 型-英国 BS1363
电源插座类型	iec 60320 C13
连接器 b 型	cee 7/7.
火灾行为	阻燃
外层护套材料	pvc
接头 a 角度	直向
接头 b 角度	直角
接头 a 性别	母
接头 b 极性	公
接线端子	黄铜
导体	3 线
应用	diy 和家居装修维护工作家庭娱乐（电视、卫星盒、路由器等） 工业机器和设备办公桌（监控器、计算机、电话）任何需要由电源供电的电气设备

电气规格

额定电流	10A
额定电压	250V
绝缘电阻	>10MΩ
电缆固定	0.5mm ² -1mm ² >30N 1.25mm ² -1.5mm ² >60N
电气强度	2.5kV 50Hz
安全测试	4.4kV 50Hz
电容	95.08pF/m
电感	0.43μH/m

机械规格

长度	15m
横截面积	7mm
重量	175g
拔出力	10N-50N
量规	1.5mm ²
铜线绞线	48 股 0.202 毫米的绞线 ²

操作环境规格


最大引脚温度	65°C
--------	------

认证

合规性 / 认证	ce / ur / cur
符合标准	iec 60320




ASSEMBLY :

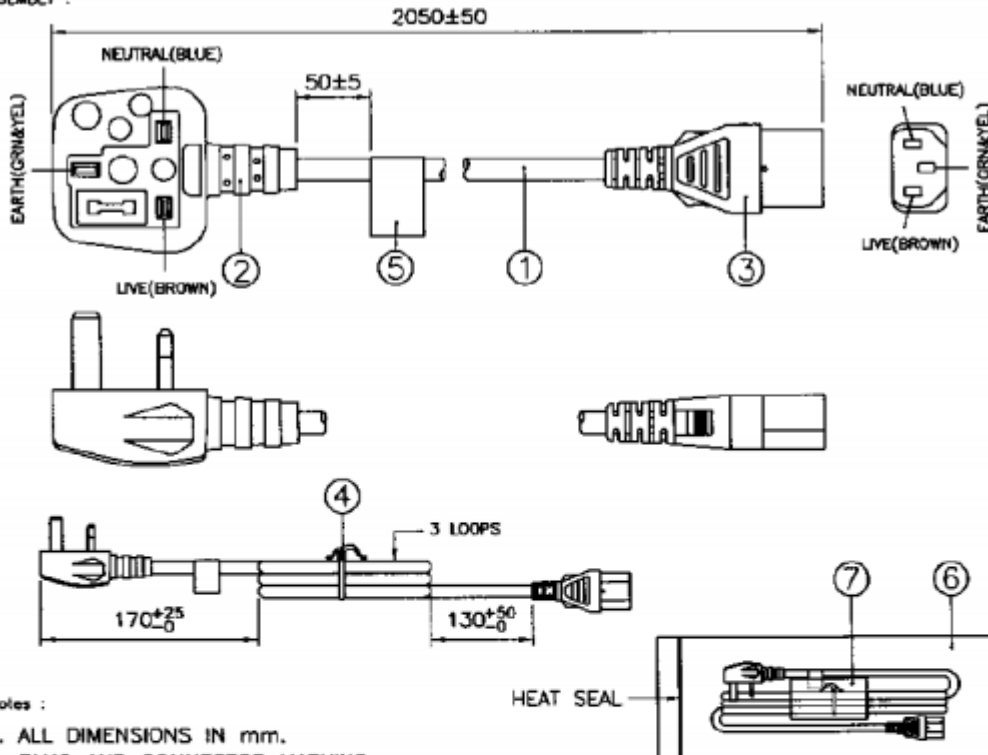

Notes :

1. ALL DIMENSIONS IN mm.
2. PLUG AND CONNECTOR MARKING :
REFER TO MARKING DRAWING NO. : VP-0401 AND VC-0402 RESPECTIVELY.
3. PLUG AND CONNECTOR DETAILS :
REFER TO PRODUCT DRAWING NO. : P-0013 AND C-0063 RESPECTIVELY.
4. THIS PART CAN BE MANUFACTURED AT ANY LOCATION WHICH HAS SAFETY APPROVAL.

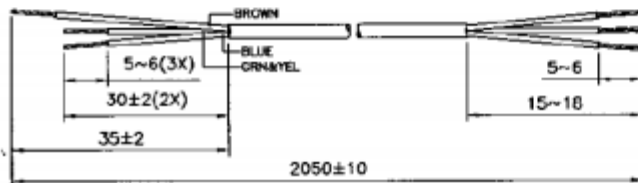

CABLE CUTTING

CABLE SOURCE :

1. BAO HING(SHENZHEN).
2. TONG YUAN(SHENZHEN).
3. TA HSING(SHENZHEN).