

Features

- Simple push fit
- Clean, neat finish
- Re-useable
- No tooling required
- Suitable for light duty applications

RS PRO Rivets

RS Stock No.: See Table



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

- *Expanding push-in Snap Rivets are easy to install*
- *Push the head in and the grommet expands for a tight fit*
- *Removable by simply pulling the head*
- *Typical applications for snap rivets include lighting, motor vehicles, domestic appliances, audio equipment and furniture.*

Material Specifications

Material Type	Nylon 6
Rivet Type	Snap
Colour	White
Finish	Plain
Flammability Rating	UL94-V2
Working Temperature Range	-30°C to +75°C

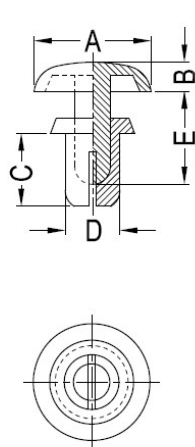


Fig. 1

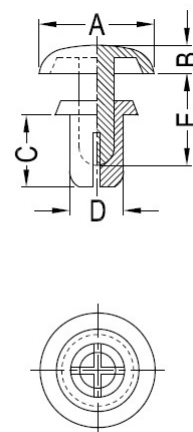
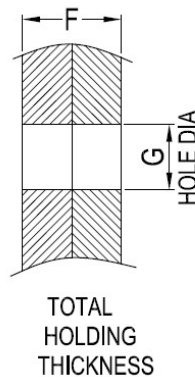


Fig. 2

Part Specifications

Stock#	G (Fixing Hole Dia.)	Extractio n Force Kgf (Min)	F (Grip Range)	A (Head Dia.)	B (Head Height)	C (Rivet Length)	D (Rivet Dia.)	E	Fig
0304053	2.1-2.2	3.0	0.6-1.2	4.2	1.2	2.4	2	2.8	1
0304055			1.3-2.0			3.2		3.8	
0304058			2.1-2.8			4.0		5.5	
0304061			2.9-3.6			4.8		5.5	
0304064			3.7-4.4			5.6		7.2	
0304067			4.4-5.2			6.4			
0304200	2.7-2.8	3.0	1.0-2.0	5.0	1.4	3.2	2.6	4.6	
0304203			2.0-3.0			4.2		6.2	
0304206			2.7-3.6			4.8			
0304209			3.4-4.3			5.5			
0304212			4.3-5.2			6.4			
0304215			5.1-6.0			7.2		7.8	
0304218	3.1-3.2	7.0	1.0-2.0	6.4	1.6	3.5	3.0	5.1	
0304221			2.0-3.0			4.5		6.1	
0304224			2.5-3.5			5.0			
0304227			3.0-4.0			5.5			
0304229			4.0-5.0			6.5		7.1	
0304231			5.0-6.0			7.5		9.0	
0304234			5.5-6.5			8.0		11.0	
0304237			6.5-7.5			9.0			
0304240			7.5-8.5			10.0			
0304070						11.5-13.0			14.5
0304073	4.1-4.2	15.0	1.7-2.5	8.0	1.8	4.0	4.0	5.0	2
0304076			2.5-3.5			5.0		7.1	
0304079			3.0-4.0			5.5			
0304082			3.5-4.5			6.0			
0304085			4.5-5.5			7.0		9.0	
0304088			5.5-6.5			8.0		9.0	
0304091			6.5-7.5			9.0		11.0	
0304094			7.5-8.5			10.0		11.0	
0304097			9.0-10.5			12.0		14.0	
0304099			12.5-14.0			15.5		16.6	
0304102	5.1-5.2	20.0	1.5-2.5	9.0	2.2	4.5	5.0	6.5	
0304105			2.5-3.5			5.5		6.5	
0304108			3.5-4.5			6.5		8.5	
0304243			4.5-5.5			7.5		8.5	
0304246			5.5-6.5			8.5		10.5	
0304249	6.1-6.2	30.0	2.5-4.0	12.0	2.5	6.0	9.0		
0304252			3.5-5.5		3.0		8.0	10.0	