




SIVACON, side panel / rear panel, Closed, IP40, H: 1800 mm, W: 800 mm, RAL 7035

Model			
product brand name		SIVACON	
product designation		Side panel/rear panel	
design of the product		Closed	
design of the surface		Powder-coated	
design of the product EMC version		No	
Protection class			
protection class IP		IP40	
Appearance			
RAL color number		RAL 7035	
color		light grey	
Product details			
product component			
• cable entry		No	
• lock		No	
Mechanical Design			
height		1 800 mm	
width		800 mm	
depth		800 mm	
material		steel	
Approvals Certificates			
General Product Approval		Test Certificates	other
		Special Test Certificate	Confirmation
			Miscellaneous
			
other		Environment	
Miscellaneous		Environmental Confirmations	
			

Further information	
Information on the packaging	
https://support.industry.siemens.com/cs/ww/en/view/109813875	
Information- and Downloadcenter (Catalogs, Brochures,...)	
http://www.siemens.com/lowvoltage/catalogs	

Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1880-2UW60-1C>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1880-2UW60-1C>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1880-2UW60-1C
CAx-Online-Generator
<http://www.siemens.com/cax>
Tender specifications
<http://www.siemens.com/specifications>

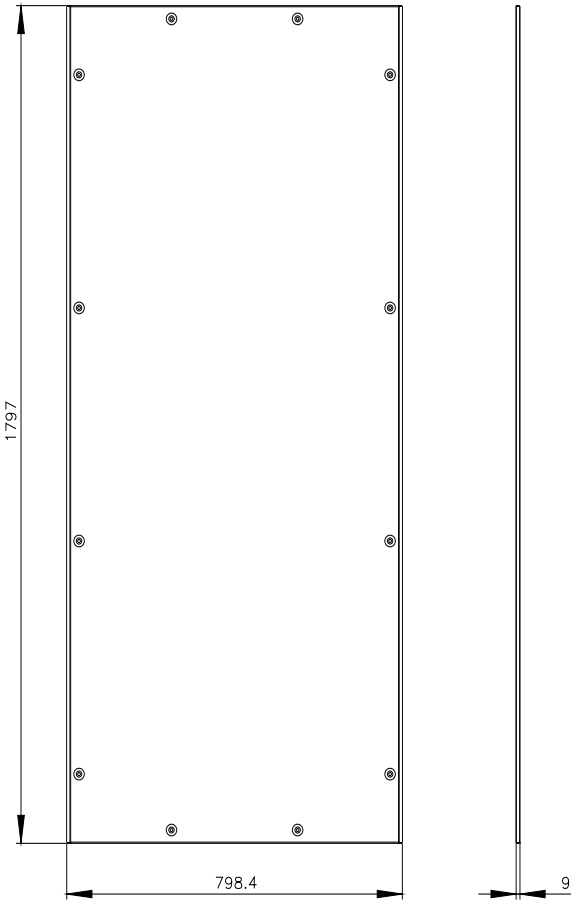

last modified: 5/24/2025

