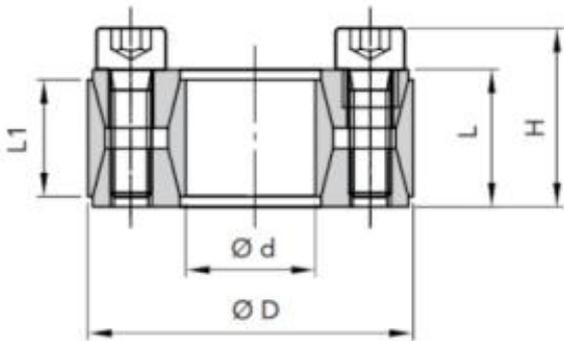


06400020

RCK 40 - Not self centering

2D Technical Drawing

Dynamic 3D View

Technical Specifications

Part number (CODE)	06400020
Ød (DD) mm	20
ØD (D) mm	47
L1 (L1) mm	17
L (L) mm	20
H (H) mm	28
Maximum torque Mt (MT) Nm	270
Clamping pressure - Shaft (CPS) N/mm ²	210
Clamping pressure - Hub (CPH) N/mm ²	90
Clamping screws DIN 912 MAT. 12.9 - N. (CSN)	8
Clamping screws DIN 912 MAT. 12.9 - Type (CSTY)	M6x18
Clamping screws DIN 912 MAT. 12.9 - Torque (CSTO) Nm	14
Extraction thread - Type (ETT)	M8
Extraction thread - N. (ETN)	2
Weight (WEIGHT) kg	0.24