


## LED Bulkhead with Dimming Sensor



MLA part code	BT14A	BT20A
Description	LED Bulkhead With Dimming Sensor	LED Bulkhead With Dimming Sensor
Weight (kg)	0.85	1.15
ErP Class	A	A
Overall dimensions (mm)	315 (d) 74 (p)	380 (d) 81 (p)
Wattage (W)	14	20
Lumens (lm)	910	1450
Efficacy (lm/W)	65	72
Diffuser	Opal	
CCT	4000K	
LED Colour	Cool White	
Class	Class II double insulated	
IP rating	IP44	
Input voltage	Mains 230V 50Hz	
Construction	Polycarbonate	
Finish	White	
Warranty	3 Years	
Photometric data	Yes	
Instruction sheet	Yes	
Origin of Manufacture	China	
Declaration of Conformity (held on file)	Yes	
Manufactured & accordance with	EN60598	
EAN	5055832941187	5055832933182

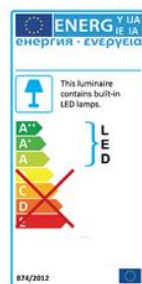