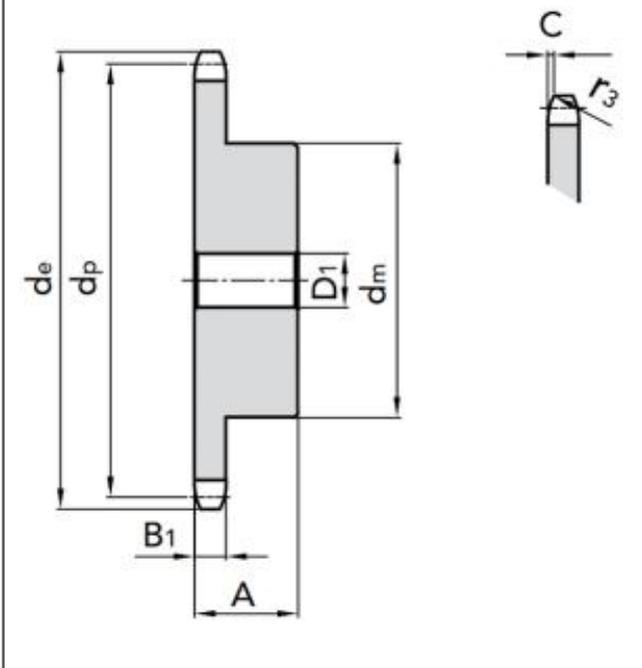


10115020

pitch 5/8in x 3/8in - Chain sprockets ASA

2D Technical Drawing

Dynamic 3D View

Technical Specifications

Number of teeth (T)	20
de (DE) mm	108.40
dp (DP) mm	101.49
Part number (CODE)	10115020
dm (DM) mm	75
D1 (D1) mm	14
A (A) mm	30
Tooth radius r3 (R3) mm	17
Radius width C (C) mm	2
Sprockets tooth width B1 (B1) mm	9
Weight (WEIGHT) kg	1.21
Material (MAT)	STEEL C45