


PACITEC® Plastic Enclosures

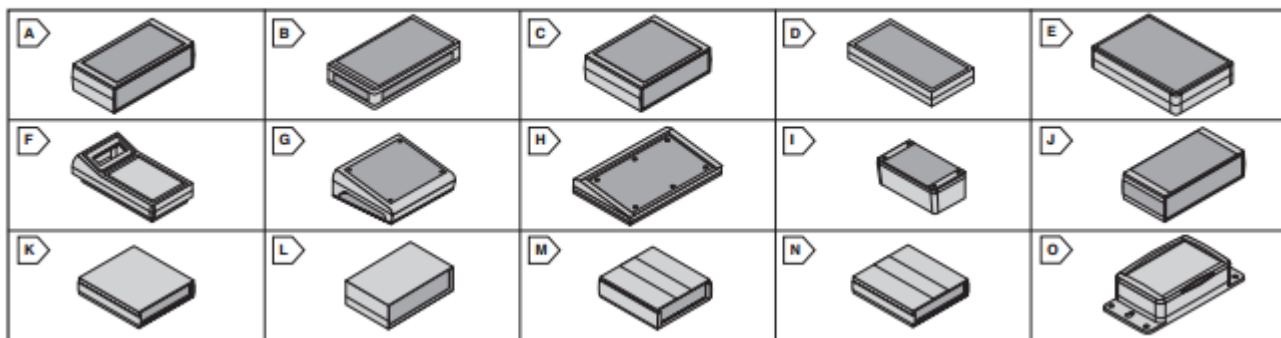

PACITEC® HANDHELD ENCLOSURES

Fig.	PacTec Model No.	Pactec Part Number		Dimensions: in.				
		Black	Bone	L	W	H	PC Board	
A	JM-12IE	71971-510-000	71972-510-039	2.40	1.60	0.80	1.90	1.10
A	JM-22	69313-510-000	69316-510-039	2.40	2.20	1.00	1.90	1.70
A	JM-42	71867-510-000	71868-510-039	3.80	2.40	1.00	3.30	1.90
B	HM-9VB	61980-510-000	61985-510-039	3.80	2.40	1.00	3.10	1.90
C	HML	62558-510-000	62562-510-039	4.60	2.70	0.90	4.10	2.20
C	HML-9VB	62578-510-000	62582-510-039	4.60	2.70	1.00	4.10	2.20
D	HP	60616-510-000	61989-510-039	5.70	3.60	1.10	5.20	3.10
D	HP-9VB	60620-510-000	62006-510-039	5.70	3.60	1.20	5.20	3.10
E	HPL	60624-510-000	62040-510-039	7.50	4.10	1.10	7.00	3.60
E	HPL-9VB	60628-510-000	62057-510-039	7.50	4.10	1.20	7.00	3.60
F	HPS	60607-510-000	62016-510-039	5.70	3.60	1.10	5.20	3.10
F	HPS-9VB	60611-510-000	62036-510-039	5.70	3.60	1.30	5.20	3.10

PACITEC® KEYBOARD ENCLOSURES

G	PT-8	82399-510-000	82399-510-039	6.60	8.90	2.70	6.10	8.40
G	PT-10	82404-510-000	82404-510-039	7.90	11.00	3.00	7.40	10.50
H	KEU-5LP	73700-510-000	73701-510-039	5.40	5.40	1.50	4.90	4.90
H	KEU-7	63100-510-000	63104-510-039	5.10	7.10	3.00	4.60	6.60
H	KEU-10	62291-510-000	62290-510-039	8.10	10.10	4.00	7.60	9.60
H	KEU-10LP	72556-510-000	72557-510-039	8.10	10.10	2.10	7.60	9.60

PACITEC® UTILITY ENCLOSURES

I	FLX-2535	74921-510-028	74922-510-060	3.50	2.50	1.10	3.00	2.00
I	FLX-4624	74980-510-028	74981-510-060	4.60	2.40	1.30	4.10	1.90
I	FLXT-2535	74923-510-028	74924-510-060	3.50	2.50	1.10	3.00	2.00
I	FLXT-4624	74982-510-028	74983-510-060	4.60	2.40	1.30	4.10	1.90

PACITEC® DESKTOP ENCLOSURES

J	LH43-100	75054-510-000	75053-510-039	3.10	4.50	1.20	2.60	4.00
J	LH43-200	75815-510-000	75816-510-039	3.10	4.50	1.70	2.60	4.00
J	LH45-175	79160-510-000	79160-510-039	4.70	4.10	1.70	4.20	3.60
J	LH55-130	71886-510-000	71887-510-039	5.10	5.10	1.50	4.60	4.60
J	LH55-200	71988-510-000	71989-510-039	5.10	5.10	2.20	4.60	4.60
J	LH57-130	74216-510-000	74217-510-039	7.20	5.50	1.50	6.70	5.00
J	LH64-130	71894-510-000	71895-510-039	4.20	6.10	1.50	3.70	5.60
J	LH84-130	71902-510-000	71903-510-039	4.20	8.10	1.50	3.70	7.60
J	LH95-130	74208-510-000	74209-510-039	6.20	9.10	1.50	5.70	8.60
J	LH95-200	74212-510-000	74213-510-039	6.20	9.10	2.20	5.70	8.60
J	LH129-250	76445-510-000	76445-510-039	9.30	11.10	2.20	8.80	10.60
K	CM3-100	71913-510-000	71914-510-039	5.20	3.30	1.20	4.70	2.80
K	CM3-150	63000-510-000	62999-510-039	5.20	3.30	1.70	4.70	2.80
K	CM5-125	63050-510-000	63049-510-039	5.20	5.10	1.50	4.70	4.60
K	CM5-200	64025-510-000	61956-510-039	5.20	5.10	2.20	4.70	4.60
K	CM6-150	71921-510-000	71922-510-039	6.20	6.10	1.70	5.70	5.60
K	CM6-225	63075-510-000	63074-510-039	6.20	6.10	2.50	5.70	5.60
K	CM6-300	64000-510-000	63999-510-039	6.20	6.10	3.20	5.70	5.60
K	CM69-180	63240-510-000	63244-510-039	9.50	6.30	1.90	9.00	5.80
K	CM69-240	63270-510-000	63274-510-039	9.50	6.30	2.50	9.00	5.80
K	CM85-225	63025-510-000	63024-510-039	6.20	8.10	2.50	5.70	7.60
L	DM-2	72500-510-000	72494-510-039	11.40	10.40	2.30	10.90	9.90
L	DM-3	72501-510-000	72495-510-039	11.40	10.40	3.30	10.90	9.90
L	DM-4	72502-510-000	72496-510-039	11.40	10.40	4.30	10.90	9.90
M	C-23	61000-510-000	61866-510-039	9.20	8.50	2.4-3.6	8.70	8.00
N	CF-275	63210-510-000	63214-510-039	9.10	8.30	3.10	8.60	7.80

PACITEC® OUTDOOR/IP RATED ENCLOSURES

Fig.	PacTec Model No.	Pactec Part Number		Dimensions: in.				
		Gray	...	L	W	H	PC Board	
O	OD-45	82365-510-332	...	5.10	3.10	1.50	4.60	2.60
O	OD-56	82428-510-332	...	6.00	5.00	1.50	5.50	4.50