

RS Pro Datasheet – Fiche Technique – Datenblatt

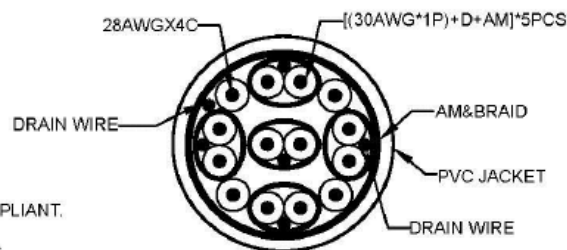
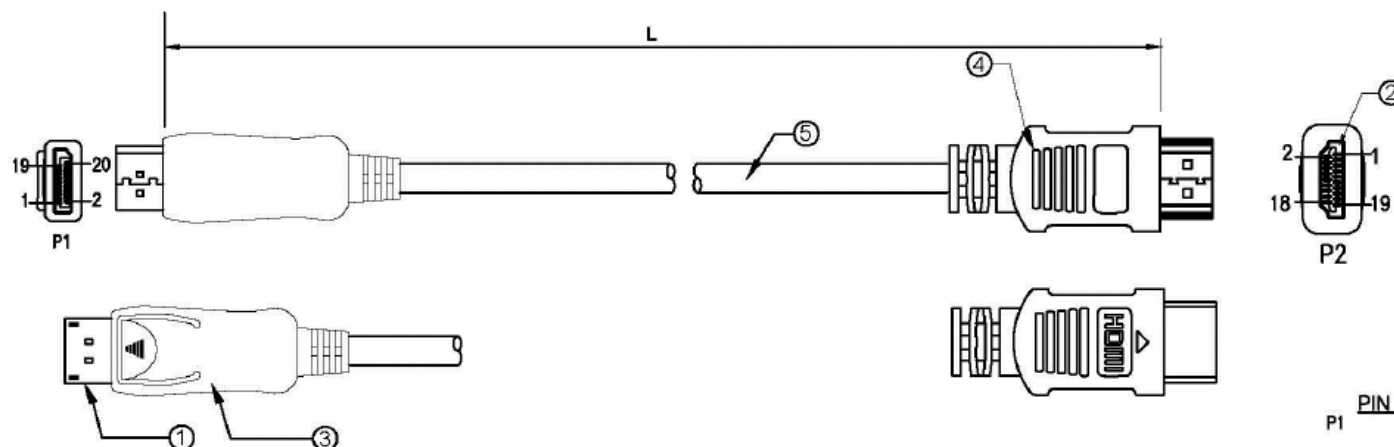
RS Pro: 144-8601



VALUE DisplayPort Cable, DP - HDTV, M/M, black, 1.0 m

VALUE Câble DisplayPort DP - HDTV, M/M, noir, 1.0 m

VALUE DisplayPort Kabel DP - HDTV, ST/ST, schwarz, 1.0 m

**NOTE:****1. Electrical properties:**

1. ALL COMPONENTS ARE RoHS COMPLIANT.
2. 100% OPEN AND SHORT TEST.
3. CONDUCTOR RESISTANCE: 3 OHMS
4. INSULATION RESISTANCE: 10 MEGOHMS.
5. HI-POT: DC200V/0.01S
6. PC TEST 4K*2K 30Hz PASS 1080P PASS

2. RoHS compliant.**MATERIAL LIST****MODEL LIST**

Model	Length	DSP
11.99.5780	1000mm	4K*2K 30HZ
11.99.5781	2000mm	4K*2K 30HZ
11.99.5782	3000mm	4K*2K 30HZ
11.99.5783	4500mm	4K*2K 30HZ

PIN ASSIGNMENT:

FIN ASSIGNMENT			
P1		P2	
3	PCB	3	
1		1	
2		2	
6		6	
4		4	
5		5	
9		9	
7		7	
8		8	
12		12	
10		10	
11		11	
15		15	
16		16	
17		17	
18		18	
19		19	
SHELL			SHELL

⑤	CABLE	(7/0.10BC*1P+7/0.10BC+AM)*5PCS+7/0.12BC*4C+AM+7/0.12BC+128/0.12 AL-MG+PVC, OD: 7.3±0.1mm, COLOR: BLACK	L					
④	OUTER MOLD	BLACK PVC	1	DRAW No.		NAME	VALUE DisplayPort Cable, DP+HDTV, MM, black	
③	OUTER MOLD	BLACK ABS	1	CUSTOMER		MAPE	TOLERANCE	
②	CONNECTOR	HDMI MALE, GOLD PLATED PIN, NICKEL PLATED SHELL	1	MODEL No.	11.99.578X		X. ±1.00 X.X ±0.50	
①	CONNECTOR	DisplayPort MALE, GOLD PLATED PIN, NICKEL PLATED SHELL	1	APPROVE BY	CHECK BY	DRAW BY	SCALE	MM
No.	PART NAME	DESCRIPTION	QTY				PAGE	1/1