

ARCA 403021T No MP



Sample image

Order symbol : ARCA 403021T No MP

Product nr : 8121007N

Description : Cabinet, PC



Remarks : Transparent cover, 2-point locking, hinges on the long side, without mountingplate

EAN : 6418074317957

El. number :

- Finland : 3425129
- Denmark : 8212056446
- Sweden : 2507047

Including : Cabinet base, door with PUR gasket. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

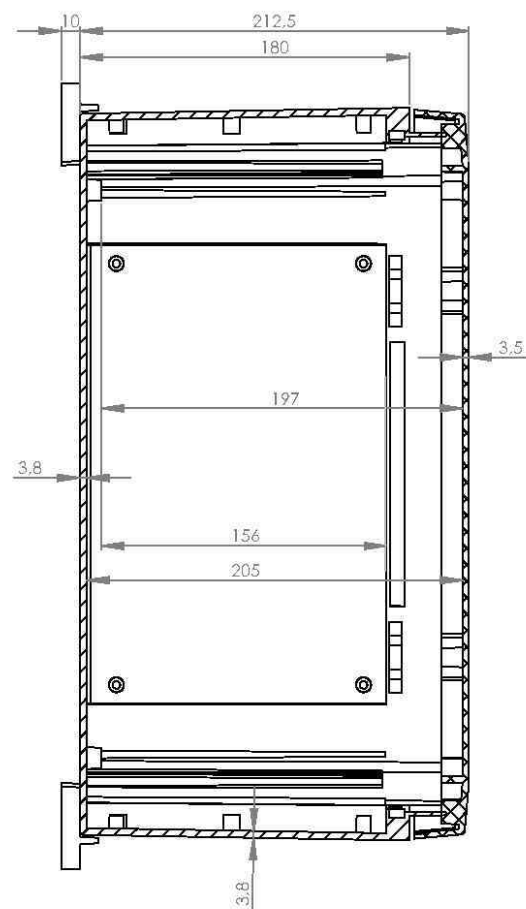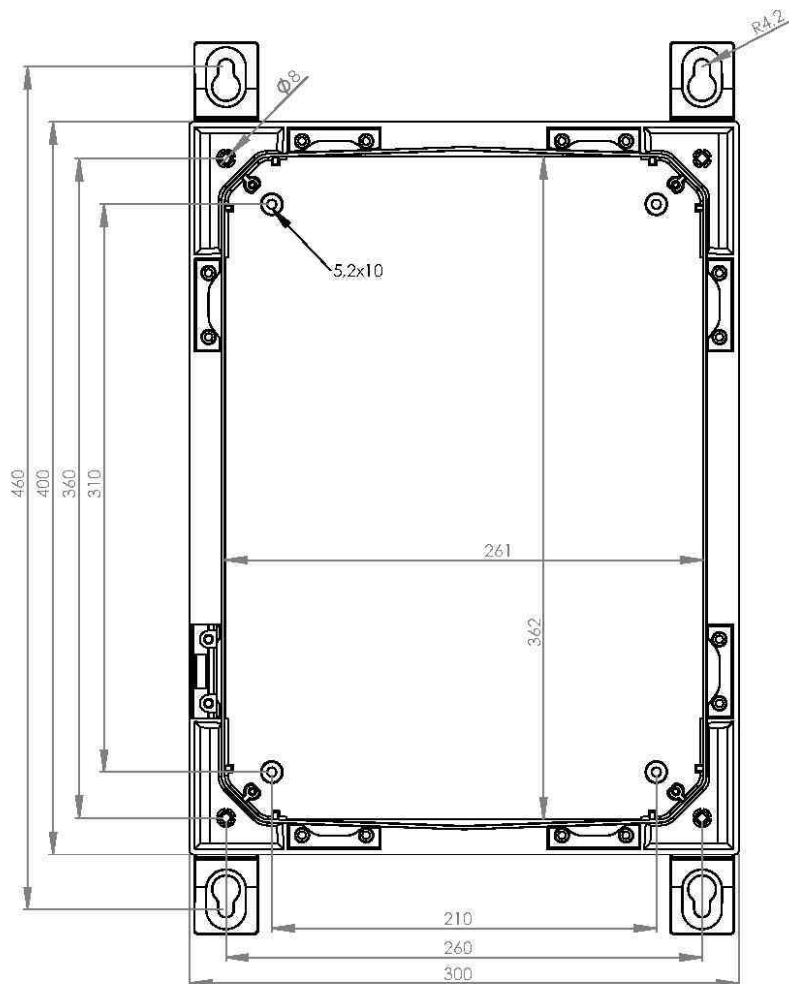

Dimensions :

	Height	Width	Depth
mm :	400	300	210
inch :	15.75	11.81	8.27

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	Smoked grey
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

Accessories :

DRS ARCA 403021	DIN rail frame set (385 x 285 x 35)
RCS ARCA 4030	Rain canopy set for size 4030 and 3030 (30 x 300 x 20)
IDS ARCA 4030	Inner door set (385 x 285 x 35)
PMK ARCA 30	PoleMounting kit, for pole ø100-300mm (385 x 285 x 35)
DSP ARCA VLS	Door stopper ARCA, vertical, left, small (15 x 104 x 16)
MPMP ARCA 4030	Mounting plate multiperforated (350x250x2 mm - ø3.6 mm) (350 x 250 x 1.5)
DSP ARCA VRS	Door stopper ARCA, vertical, right, small (15 x 104 x 16)
MPS ARCA 4030	Mounting plate (350x250x2 mm) (350 x 250 x 2)
MPP ARCA 4030	Mounting plate perforated (350x250x2 mm - 26x11 mm) (350 x 250 x 2)
MPX ARCA 4030	Mounting plate (350x250 mm) (350 x 250 x 5)

Ratings :

Ingress protection (EN 60529):	IP66;
Impact Resistance (EN 62262):	IK09;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C :	960C
UL Type	1, 4, 4X, 12, 13

Certificates :
Certificate FI 40467