 




RL48-19/14

Radialvifte DC 76x76x27 mm

Kan fås med tillegg /2.



Tekniske data

Beskrivelse	Radialvifte DC 76x76x27 mm
Spenning	24 VDC
Spenningsområde	18-26,4 VDC
Effekt	5,0 W
Turtall	4400 rpm
Luftmengde	7.77 l/s
Luftmengde	28.0 m3/h
Luftmengde	16.5 CFM
Temperaturområde	-20...+70 °C
Lagertype	Kulelager
Lydeffekt	5.7 Bel
Levetid L10	ebm-papst Service Life L10: 60000 tim 40 °C / 30000 tim 70 °C Life expectancy L10Δ: 120000 tim 40 °C
Størrelse	76 x 76 x 27 mm (B x H x D)
Vekt	75 g
Art.nr.	9592207002


Se www.ebmpapst.no for oppdatert informasjon



RL48-19/14

Radialvifte DC 76x76x27 mm

Diagram

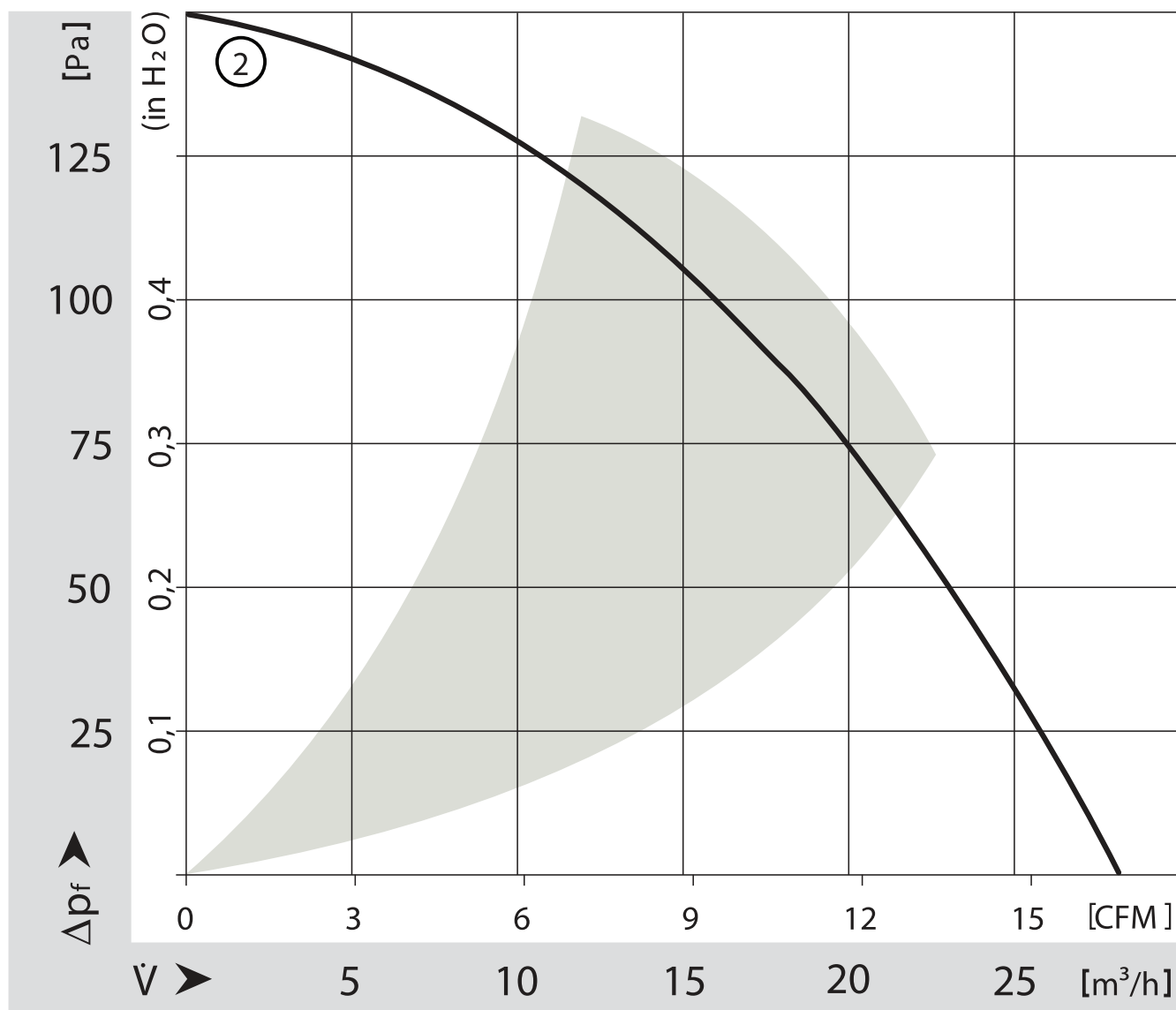




RL48-19/14

Radialvifte DC 76x76x27 mm

Tegning

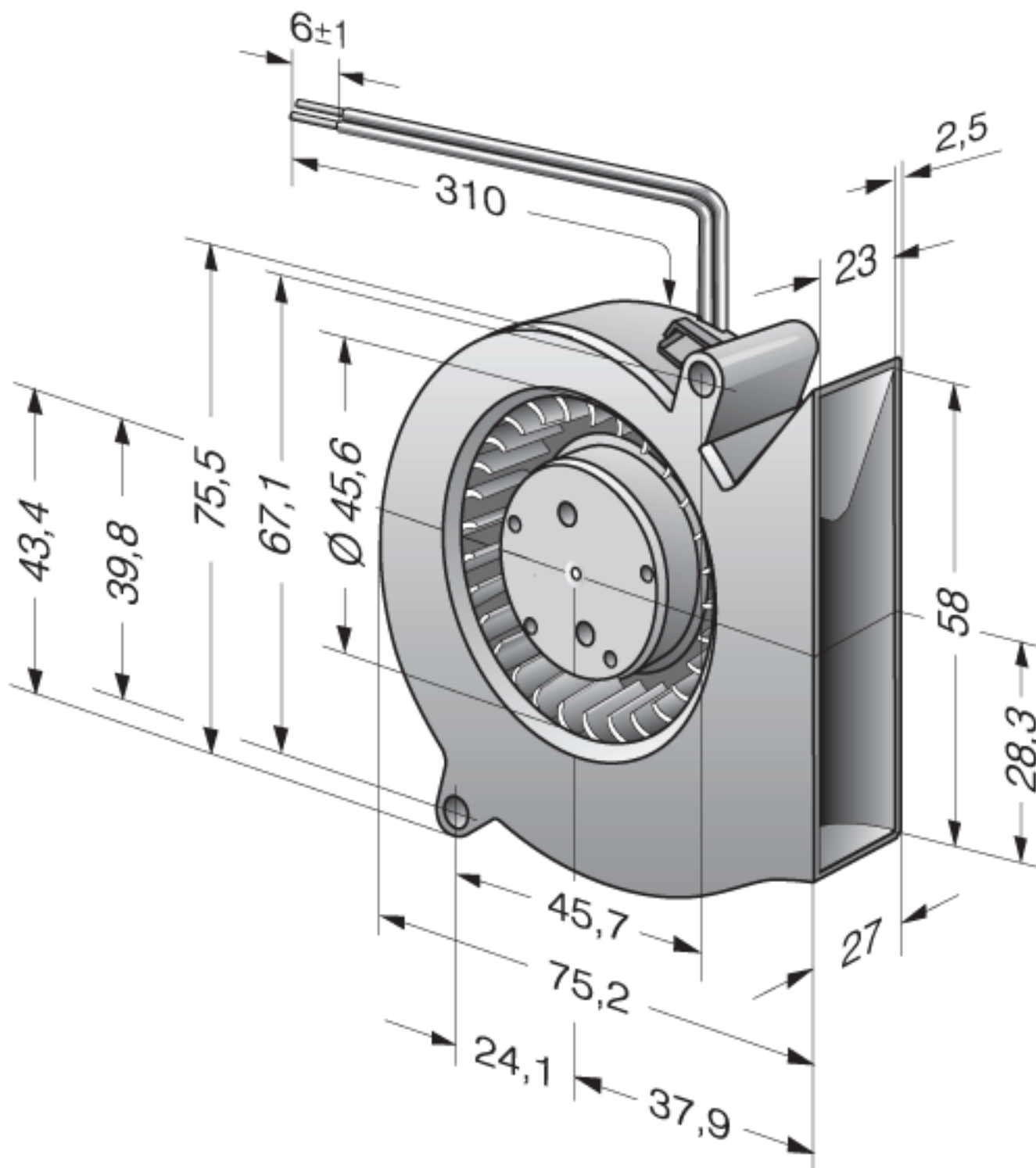



RL48-19/14

Radialvifte DC 76x76x27 mm

Kontakt

ebm-papst AS

Nordåsveien 5

1251 Oslo

Telf: 22 76 33 40

Fax: 22 61 91 73

mailbox@ebmpapst.no

www.ebmpapst.no