


Part Number: [0153660123](#)
Status: Active
Overview: [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)
Description: 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Tin (Sn) Plating, 12 Circuits, with Shield

Documents:

図面 (PDF)	Datasheet (PDF)
製品仕様書 153660001-000 (PDF)	RoHS Certificate of Compliance (PDF)

一般	
Crimp Quality Equipment	Yes
概要	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
製品名	Premo-Flex FFC Jumper
Taxonomy	Flexible Printed Circuit (FPC)
UPC	193264621590
機械的性能/材質	
ケーブル長	102.00mm
極数 (実装)	12
Contact Layout Type	A (same side)
材質 - 嵌合部メッキ	錫
梱包形態	ポリ袋
ピッチ - 嵌合部 (インチ)	0.50mm
使用温度範囲	-40° to +105° C
電線サイズ (AWG)	N/A
ケーブル種別	FFC
電気的性能	
最大定格電流	0.5A
最大定格電圧	N/A
参考情報	
図面・仕様書情報	
製品仕様書	153660001-000
製品図面	153660001-001

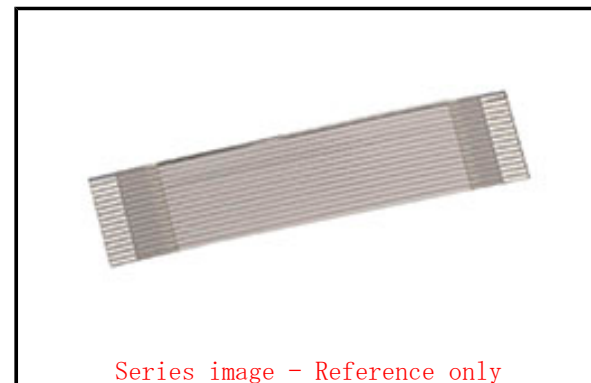

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per -	
D(2022)4187-DC (10	
June 2022)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit	
Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[15366 Series](#)

Mates With
 Easy-On FFC/FPC Connector [527451233](#) ,
[527461233](#) , [525591233](#)