




Datasheet
Stock No:

ENGLISH

359920
359936
359942
359958
359964
359970
359986
359992
360015
360021

Planar Cable

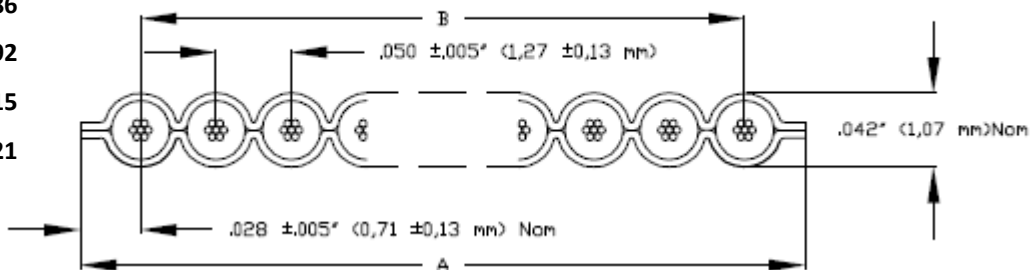

CONDUCTORS	28 AWG 7/36 tinned copper
INSULATION	0.10" PVC
LAMINATE	(2) .005" Clear PVC
COLOUR CODE	Brown, red, orange, yellow, green, blue, violet, grey, white, black, repeat.
TEMPERATURE RATING	105°C
IMPEDANCE	105 ohms
CAPACITANCE	13 pF/ft @ 1MHz
PROP DELAY	1.5 ns/ft

07/03/2016

CURRENT RATING	1.3A @ 10°C rise above ambient
VOLTAGE RATING	300 V
INSULATION RES	10 ohms 10ft minimum
APPROVALS	UL AWM style 20130

STOCK NO	NO OF CONDUCTORS	A SPAN	B SPAN"	B SPAN mm
359920	14	0.705" (17.91mm)	0.650 ±.015	16.51 ± 0.38
359936	15			
359942	16	0.805" (20.45mm)	0.750 ±.015	19.05 ± 0.38
359958	24	1.205" (30.61mm)	1.150 ±.015	29.21 ± 0.38
359964	25	1.255" (31.88mm)	1.200 ±.025	30.48 ± 0.38
359970	34	1.705" (43.31mm)	1.650 ±.015	41.91 ± 0.38
359986	36	1.805" (45.85mm)	1.750 ±.015	44.45 ± 0.38
359992	37	1.855" (47.12mm)	1.800 ±.015	45.72 ± 0.38
360015	50	2.505" (63.63mm)	2.950 ±.020	62.23 ± 0.51
360021	64	3.205" (81.41mm)	3.150 ±.020	80.01 ± 0.51

07/03/2016