



Accessories - Shelves

## Ventilated Stationary Shelves



### ***Design Features***

Stationary shelves come in widths to fit 19" and 24" wide panel spaces and all cabinet rack depths. Shelves are one-piece, 16-gauge steel with flanged front and rear to support up to 200 lbs. All shelves come with necessary mounting hardware. Additional brackets are furnished to allow flexibility in mounting. Shelves allow sufficient room in rear for cables and power outlet strips. Requires two pairs of panel mounting rails per cabinet rack. Finish: Smooth Black. Also available in Ventilated versions

Ventilated Shelves						
Catalog Number	Drawings	Cabinet Racks		Shelves		
		Panel Width	Maximum Clear Inside Depth	Width	Depth	Weight
SH-2383		19"	17"	17-29/32"	14.25"	6 lbs

SH-2384		19"	20.5"	17-29/32"	17.75"	7 lbs
SH-2385		19"	24"	17-29/32"	21.25"	8.25 lbs
SH-2386		19"	29.25"	17-29/32"	26.5"	9 lbs
SH-2483		24"	17"	22-29/32"	14.25"	7.5 lbs
SH-2484		24"	20.5"	22-29/32"	17.75"	8.25 lbs
SH-2485		24"	24"	22-29/32"	21.25"	10.25 lbs
SH-2486		24"	29.25"	22-29/32"	26.5"	11.25 lbs



PART NAME

SHELF



PART No.

SH-2379 TO SH-2486

MATERIAL: 16 GA. STEEL

FINISH:  
SMOOTH BLACK

LOAD RATING: 200 LBS. MAX.

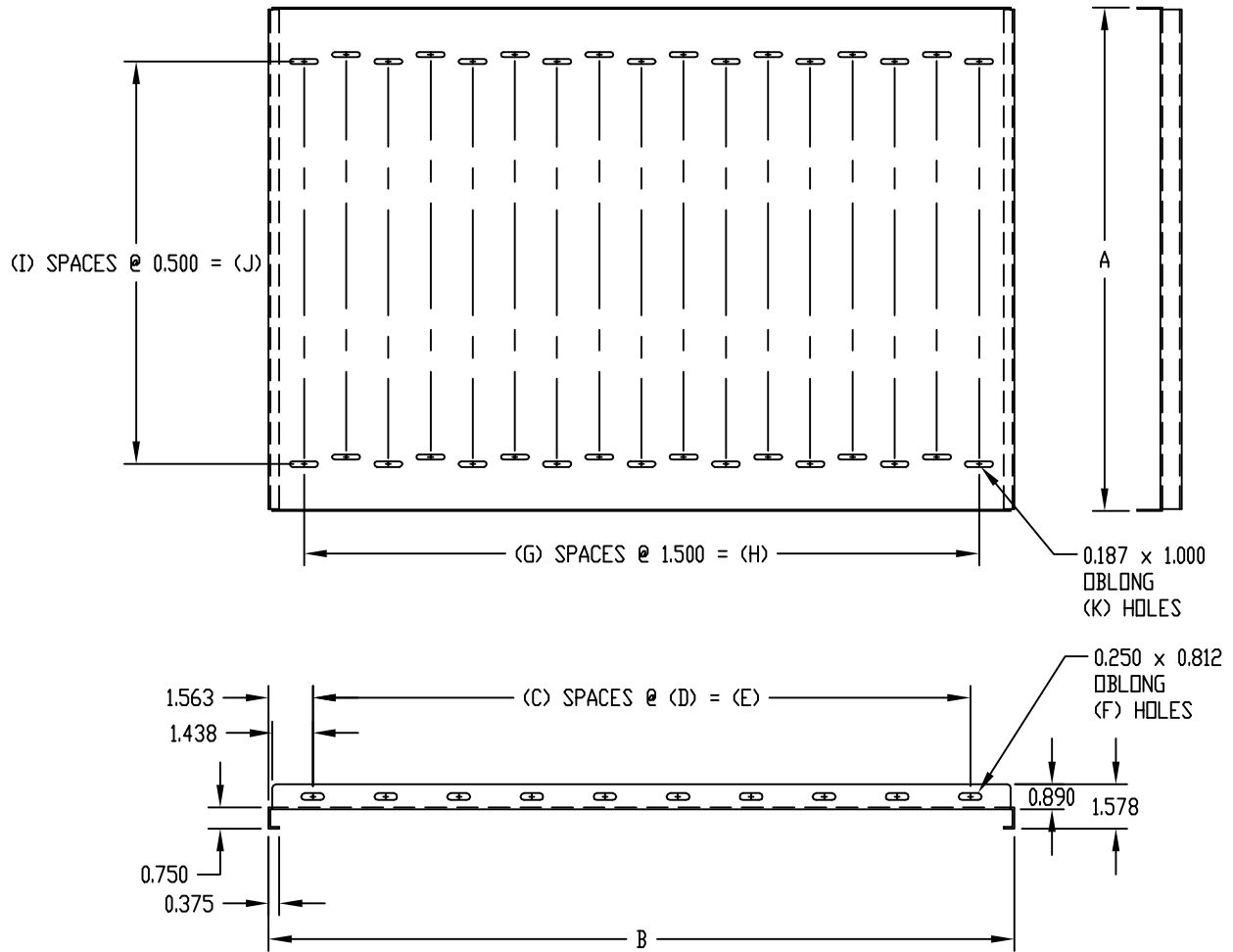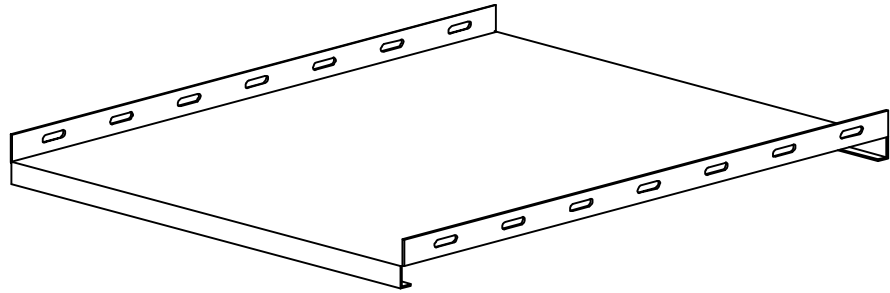

PART NO.		A	B	C	D	E	F	G	H	I	J	K
PLAIN	VENTED											
SH-2379	SH-2383	17.906	14.250	4	2.781	11.125	10	8	12.000	29	14.500	270
—	SH-2384		17.750	6	2.438	14.625	14	10	15.000			330
—	SH-2385		21.250	7	2.589	18.125	16	12	18.000			390
SH-2382	SH-2386	17.906	26.500	9	2.597	23.375	20	16	24.000	29	14.500	510
SH-2479	SH-2483	22.906	14.250	4	2.781	11.125	10	8	12.000	41	20.500	378
SH-2480	SH-2484		17.750	6	2.438	14.625	14	10	15.000			462
SH-2481	SH-2485		21.250	7	2.589	18.125	16	12	18.000			546
SH-2482	SH-2486	22.906	26.500	9	2.597	23.375	20	16	24.000	41	20.500	714