



Similar to image

Technical data:		
Type of mounting		surface mounted
Height	mm	151
Width	mm	66
Depth	mm	54
Material		thermoplastic
Appearance		shiny
Design of the operating mechanism		rocker/button
Design of the socket		SCHUKO
Built in orientation		vertical
Switch design		toggle switch
Color		grey
Number of sockets		1
Program start		-
Surface processing		others
Breaking capacity current	A	10
Product feature / halogen-free		Yes
Operating voltage / nominal value	V	250
material / of the housing		plastic

Product component / integrated / Fluorescent materials		No
Operating current / [nicht versorgt - der Steckdose] / [nicht versorgt - Nennwert]	A	16
Protection class IP		IP44
type of the assembly		fixing with screw

Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Global Industry Mall (Online ordering system)


<http://www.siemens.com/lowvoltage/ mall>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/5TA4816/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=5TA4816

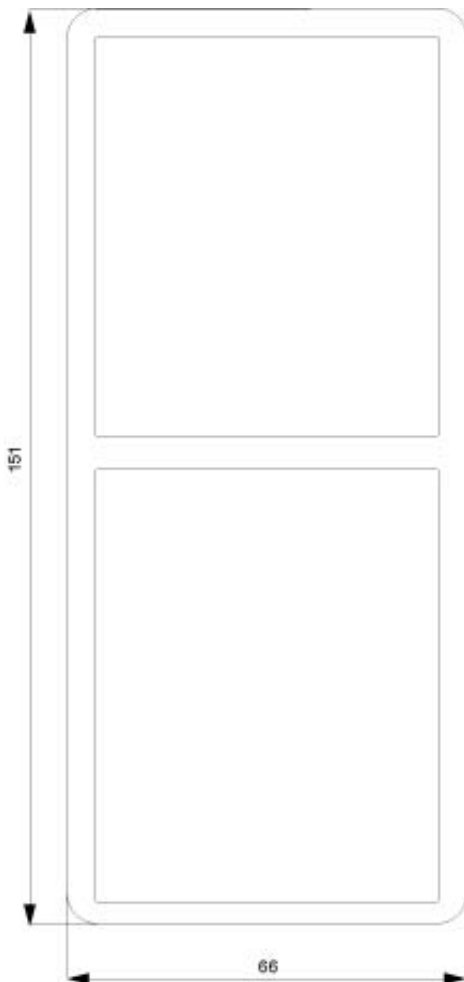

last change:

Dec 6, 2010