

381167789	DATA SHEET	
Valid from: 11.07.2025	EPIC® M23P RECEPTACLE	

Description

- Circular connectors for servomotors and power supply
- Screw locking M 23 x 1, with vibration protection O-ring
- Quickflex ready
- High power at smallest installation space
- Optimal solution for electric motors
- Quickflex speed locking system
- EMC-shielding 360°
- Safety use in field environment by high protection class



General Characteristics

Series	M23P
Version	90° angled, 330° rotatable, for male contacts
Pin configuration	5+PE
Rated voltage	630 V (2 mm contacts, Altitude 2000 m)
Rated impulse voltage	6 kV (2 mm contacts)
Rated current	30 A (2 mm contacts, at terminal cross-section 4.0 mm ²)
Contact resistance	< 4 mOhm
Contacts included	please see table below
Number of contacts	6 (5+PE)
Termination methods	Crimp termination: 0.35 – 4.0 mm ² (2 mm contacts)
Device Mounting	Ø 3,1 mm (4x)
IP- Protection	IP 68 (1 m, 10 h)
	optional IP 69 (for complete mated and tested system)
Mating cycles	500
Temperature range	-20°C to +130°C
	optional -50°C to +130°C (EPDM)
Pollution degree	3
Overvoltage category	III

Materials and Surfaces

Housing	Zinc diecast, nickel plated, chromated (CrVI free)
Insert	PA
Contacts	Brass, gold plated
Seal	FKM

Approvals

Creator: IVSE1/BU EPIC Released: THB01/BU EPIC	Document: DB381167789EN Version: 00	Page 1 of 4
---	--	-------------

381167789	DATA SHEET	
Valid from: 11.07.2025	EPIC® M23P RECEPTACLE	

UL-File-Number

In progress

Standard

Safety Standard

IEC 61984; UL 1977; UL 2238

Product Variation

Article number	Article description	Contacts included	Pin configuration	Package unit [pc]
381167787	EPIC M23P QUICK LOCK READY FLANGE 25 RECEPTACLE NICKEL PLATED	no		20
381167788	EPIC M23P QUICK LOCK READY FLANGE 28 RECEPTACLE NICKEL PLATED	no		20
381167789	EPIC M23P 6-PIN QUICK LOCK READY FLANGE 25 RECEPTACLE NICKEL PLATED	yes	5+PE	1
381167790	EPIC M23P 6-PIN QUICK LOCK READY FLANGE 28 RECEPTACLE NICKEL PLATED	yes	5+PE	1
381167843	EPIC M23P QUICK LOCK READY FLANGE 25 RECEPTACLE CHROMATED	no		20
381167844	EPIC M23P QUICK LOCK READY FLANGE 28 RECEPTACLE CHROMATED	no		20
381167845	EPIC M23P 6-PIN QUICK LOCK READY FLANGE 25 RECEPTACLE CHROMATED	yes	5+PE	1
381167846	EPIC M23P 6-PIN QUICK LOCK READY FLANGE 28 RECEPTACLE CHROMATED	yes	5+PE	1
381167849	EPIC M23P QUICK LOCK READY FLANGE 25 RECEPTACLE NICKEL PLATED	no		20
381167850	EPIC M23P QUICK LOCK READY FLANGE 28 RECEPTACLE NICKEL PLATED	no		20
381167851	EPIC M23P QUICK LOCK READY FLANGE 25 RECEPTACLE CHROMATED	no		20
381167852	EPIC M23P QUICK LOCK READY FLANGE 28 RECEPTACLE CHROMATED	no		20


Note: Larger packaging units available on request

Creator: IVSE1/BU EPIC Released: THB01/BU EPIC	Document: DB381167789EN Version: 00	Page 2 of 4
---	--	-------------


381167789	DATA SHEET	
Valid from: 11.07.2025	EPIC® M23P RECEPTACLE	

Technical Drawings

RECEPTACLE FLANGE 25

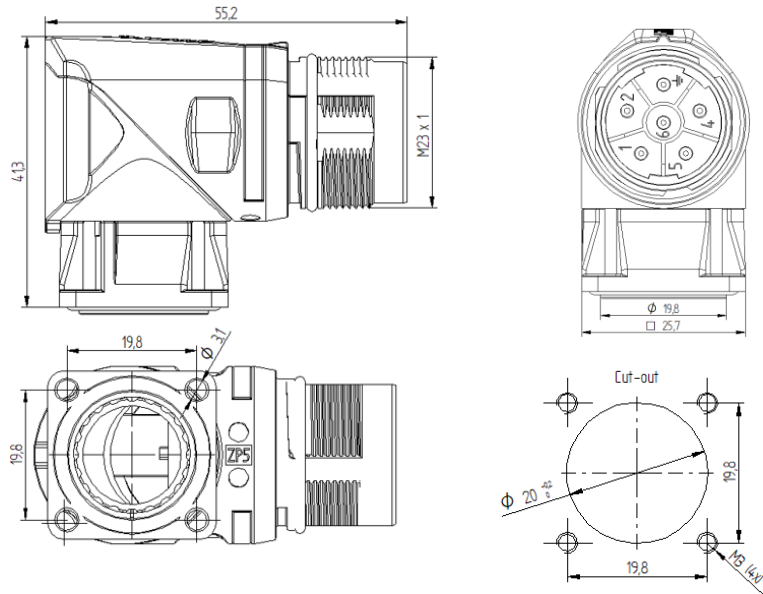

RECEPTACLE FLANGE 28

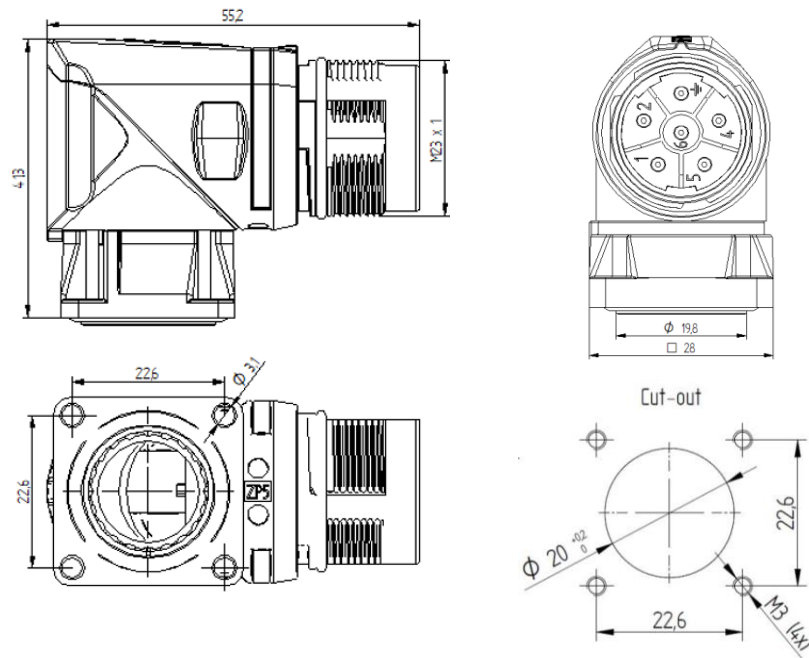

381167789	DATA SHEET	
Valid from: 11.07.2025	EPIC® M23P RECEPTACLE	



Industrial machinery and plant engineering



Mechanical resistance



Robust



Waterproof



Good chemical resistance



Corrosion-resistant



Maximum vibration protection



Assembly time



Space requirement



Wind Energy

Info

Rotateable with clearly defined adjustment positions

Application range

Plant engineering

Servo drives and servo assemblies

Remark

Photographs are not to scale and do not represent detailed images of the respective products

Creator: IVSE1/BU EPIC Released: THB01/BU EPIC	Document: DB381167789EN Version: 00	Page 4 of 4
---	--	-------------