

# IP20 FLEXIBLE LED TAPE +FLEX 160 HIGH CRI



8.2W/M



up to  
1197LM/M



IP20



Recycleable  
Cardboard



>95Ra



2700K, 3000K  
4000K, 6000K



50mm  
Cut Points



## FEATURES

- High CRI >95Ra
- Available in four different colour temperatures
- Industrial grade adhesive backing tape
- Working temperature -20°C - +45°C
- Humidity 40% - 70% RH
- 3 years warranty

## SPECIFICATIONS


| Stock Code        | 0936-206         | 1019-237         | 1181-411         | 1648-916         |
|-------------------|------------------|------------------|------------------|------------------|
| Part Code         | B7-2-160-20-95   | C0-2-160-20-95   | D0-2-160-20-95   | F0-2-160-20-95   |
| Voltage           | 24VDC            | 24VDC            | 24VDC            | 24VDC            |
| Power Consumption | 8.2W/M           | 8.2W/M           | 8.2W/M           | 8.2W/M           |
| Lumen Output      | 1080LM/M         | 1170LM/M         | 1197LM/M         | 1197LM/M         |
| Efficacy          | 132LM/W          | 143LM/W          | 146LM/W          | 146LM/W          |
| Tone (CCT)        | 2700K ●          | 3000K ●          | 4000K ●          | 6000K ●          |
| LED/metre         | 160              | 160              | 160              | 160              |
| LED Pitch         | 6.25mm           | 6.25mm           | 6.25mm           | 6.25mm           |
| Cut Points        | 50mm             | 50mm             | 50mm             | 50mm             |
| CRI               | >95Ra            | >95Ra            | >95Ra            | >95Ra            |
| IP Rating         | 20               | 20               | 20               | 20               |
| Dimensions        | 5000 x 8 x 1.2mm | 5000 x 8 x 1.2mm | 5000 x 8 x 1.2mm | 5000 x 8 x 1.2mm |




2700K



3000K

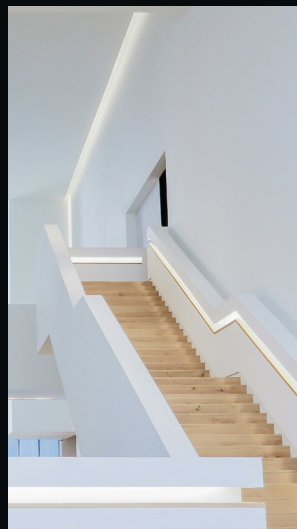

4000K

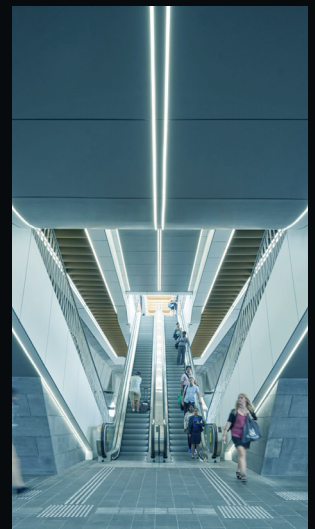

6000K

# IP20 FLEXIBLE LED TAPE +FLEX 160 HIGH CRI



## COMPATIBILITY



## CONTROL METHODS

- Bluetooth (Apps, Voice Control) - BLE-15A
- Remote Control - SCD107W

## SUGGESTED DRIVERS

| Up to 1 M                          | Up to 5 M                          | Up to 10 M                                                |
|------------------------------------|------------------------------------|-----------------------------------------------------------|
| Power supplied from <b>ONE</b> end | Power supplied from <b>ONE</b> end | Power supplied from the <b>MIDDLE</b> or <b>BOTH</b> ends |
| Non Dimmable                       | Non Dimmable                       | Non Dimmable                                              |
| PCV2420                            | PCV2450                            | PCV24101                                                  |
| Mains Dimmable                     | Mains Dimmable                     | Mains Dimmable                                            |
| UVC2425TD                          | UVC2450TD                          | UVC24100TD                                                |
| DALI Dimmable                      | DALI Dimmable                      | DALI Dimmable                                             |
| DA-30-24                           | DA-50-24                           | DA-100-24                                                 |

\*Other options available. Contact us for more information.

## MECHANICAL DIAGRAM

