



Main

Accessory / separate part category	Cabling accessories
Accessory / separate part type	Connector
Electrical connection	Straight female connector M8, 4 pins
Collar material	Metal
Status LED	Without
Cable connection	Solder terminal / wire size <math><0.25 \text{ mm}^2</math> / clamping capacity 5 mm

Complementary

Cable gland type	M9.5
Cable connector fixing	Screw-on
[Ue] rated operational voltage	60 V AC 75 V DC
[In] rated current	4 A
Enclosure material	Plastic
Minimum insulating resistance	1 G Ω
Contact resistance	5000 μOhm
Net weight	0.01 kg

Environment

IP degree of protection	IP67
Ambient air temperature for operation	-40...85 °C


Offer Sustainability

REACH Regulation	REACH Declaration
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes

Contractual warranty

Warranty	18 months
----------	-----------

Dimensions

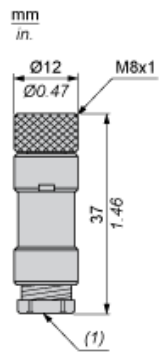

(1) Cable gland : M9.5 x 1

Connections and Schemes

