

## POLYSTEEL 600

620 Lumens | 234 m Beam | IPX8 | 4 x AA



PURE BEAM  
FOCUS  
RUBBER SPIN

High | Medium | Low  
Twist Focus

Length: 7.9" | 20 cm  
Weight: 12 oz | 340 g


Poly-nylon over stainless  
steel core

4 x AA batteries

Clam: 20791  
Box: 20792

	ANSI FL1	High	Medium	Low
Lumens	620	220	64	
Beam Distance	234m	134m	74m	
Runtime	2h	4h 30min	34h	

The Polysteel 600 is waterproof, drop proof, and crush proof, which makes this high-lumen torch ultra-durable and ready to weather any storm.

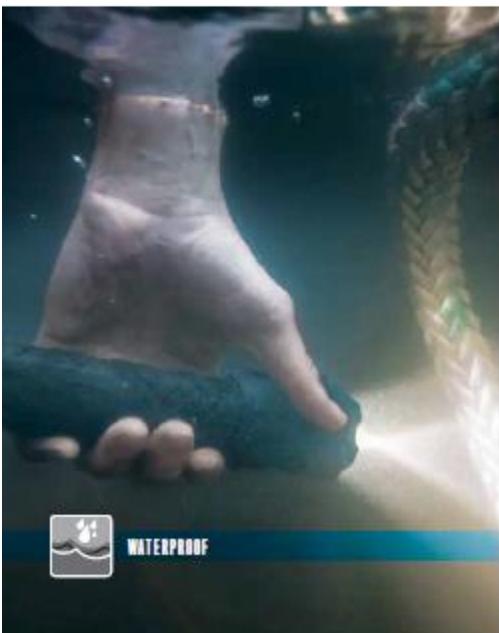

WATERPROOF

## POLYSTEEL 400

300 Lumens | 194 m Beam | IPX8 | 4 x AAA



PURE BEAM  
FOCUS  
RUBBER SPIN

High | Medium | Low  
Twist Focus

Length: 5.75" | 14.6 cm  
Weight: 6.4 oz | 181 g

Poly-nylon over stainless  
steel core

 
4 x AAA batteries

Clam: 20779  
Box: 20780

	ANSI FL1	High	Medium	Low
Lumens	300	105	33	
Beam Distance	194m	113m	62m	
Runtime	1h	3h 15min	15h	



The Polysteel 400 is waterproof, drop proof, and crush proof, all in an easy-to-handle, mid-sized package.



## POLYSTEEL 200

260 Lumens | 121 m Beam | IPX8 | 3 x AAA



PURE BEAM  
FOCUS  
RUBBER SPIN

High | Medium | Low  
Twist Focus

Length: 5.0" | 12.7 cm  
Weight: 4.1 oz | 116 g

Poly-nylon over stainless  
steel core

 
3 x AAA batteries

Clam: 20777  
Box: 20778

	ANSI FL1	High	Medium	Low
Lumens	250	87	26	
Beam Distance	121m	68m	37m	
Runtime	3h 30min	9h	36h	



The Polysteel 200 is Coast's smallest waterproof, drop proof, and crush proof torch.



CRUSH PROOF



DROP PROOF