


## Coupling

### Series M12x1 with vibration lock

Description **AN-KAB.SH53 10M WINKEL**

Article number **3251006296**

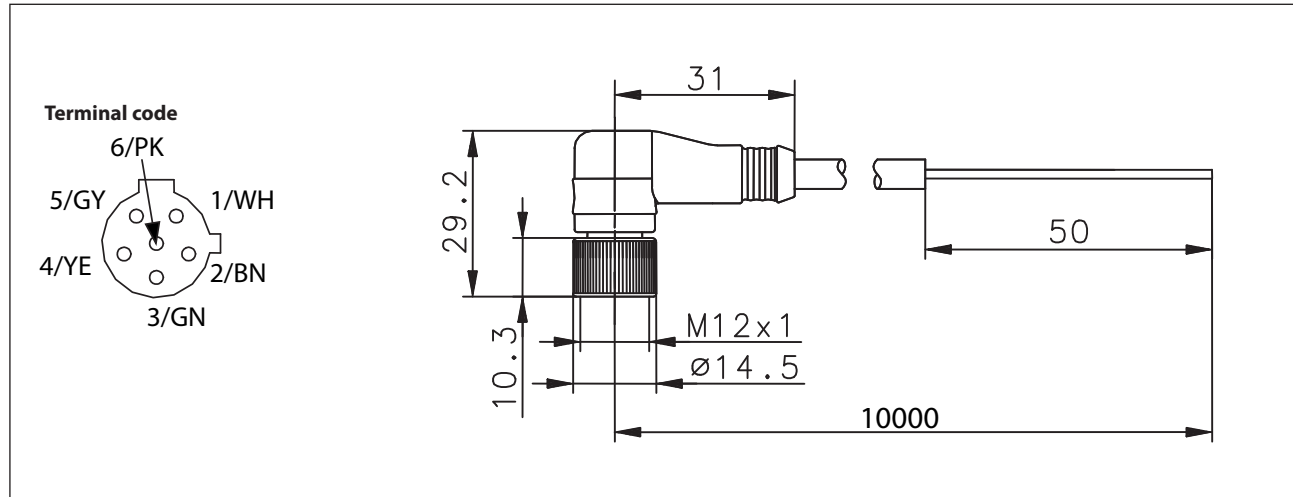

#### Electrical Data

|                       |                    |
|-----------------------|--------------------|
| Nominal voltage       | 250 V AC           |
| Rated current         | 2,5 A (at 70 °C)   |
| Insulation resistance | $\geq 10^9 \Omega$ |

#### Mechanical Data

|                      |                                                                                                  |
|----------------------|--------------------------------------------------------------------------------------------------|
| Number of contacts   | 6                                                                                                |
| Degree of protection | IP68                                                                                             |
| Temperature range    | -5 °C ... +105 °C (for flexing applications)<br>-40 °C ... +105 °C (for fixed installation)      |
| Material             | Internal pin body<br>Coupling nut<br>Moulded cable<br>Cable<br>Cable – outer jacket              |
|                      | Elastollan R3000<br>E-Coated Zinc<br>PUR<br>LiYwUL2517 6 x 0,34 mm <sup>2</sup><br>PVC (Ø5,6 mm) |